

## Cable Probe Type 03 Pt 100


### Product-Data

Sensor element:	Pt 100 Class B
Temperature range:	-50...+180 °C
Installation length:	50 mm
Diameter Installation length:	6 mm
Probe tube material	1.4571 / 1.4403
Connecting cable:	Silicone insulated Ø 4.5 mm / 4 x 0.25 mm <sup>2</sup>
Connecting cable length:	2 meters
Tmax connecting cable	+180 °C
Plug:	open wire ends
Ingress protection EN 60529:	IP 67 transition probe tube to connecting cable
Accuracy:	Class B DIN IEC 60751 +/- 0.3 °C

### Order-Information

TSG-Order-Number	8006 1103
Conrad-Order-Number	50 77 72-XX

### Dimensions

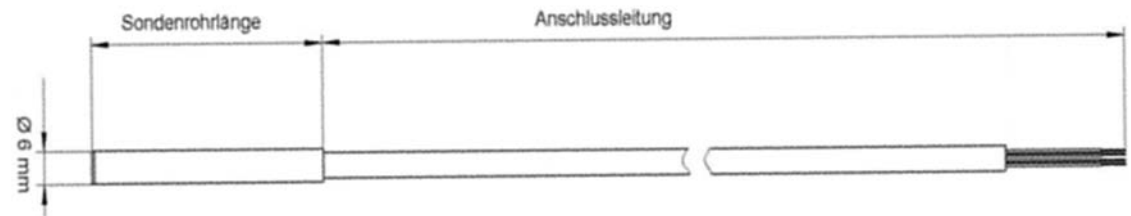

### Picture



### example of installation

