

Cable Probe Type 03 NiCr-Ni


Product-Data

Sensor element:	Pt 100 Class B
Temperature range:	-50...+400 °C
Installation length:	50 mm
Diameter Installation length:	6 mm
Probe tube material	1.4571 / 1.4403
Connecting cable:	Silicone insulated Ø 4.5 mm / 4 x 0.25 mm ²
Connecting cable length:	2 meters
Tmax connecting cable	+180 °C
Plug:	open wire ends
Ingress protection EN 60529:	IP 67 transition probe tube to connecting cable
Accuracy:	Class B DIN IEC 60751 +/- 0.3 °C

Order-Information

TSG-Order-Numbers:	8006 1104
Conrad-Order-Numbers:	50 77 73-XX

Dimensions

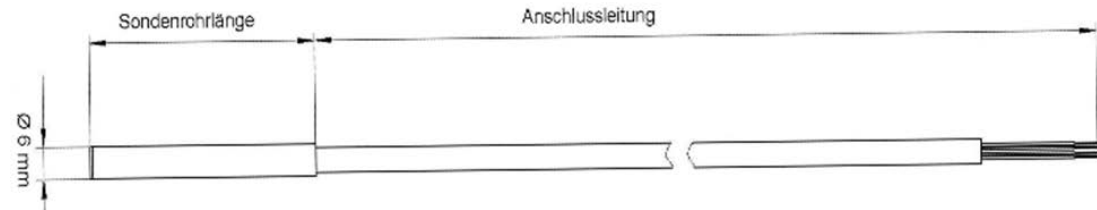

Picture



example of installation

