


Cable Probe Type 04 Pt 100

Product-Data

Sensor element:	Pt 100 Class B
Temperature range:	-50...+ 400 °C
Installation length:	100 mm
Diameter Installation length:	3 mm
Probe tube material	Stainless Steel 4.4571 / 1.4403
Sleeve:	6 x 40 mm 1.4305 bzw. CuZn nickel plated
Connecting cable:	PVC insulated Ø 4,5 mm / 4 x 0,14 mm ²
Connecting cable length:	2 meters
Tmax connecting cable:	+ 80 °C
Plug:	open wire ends
Ingress protection EN 60529:	IP 42 transition probe tube to connecting cable
Accuracy:	Class B DIN IEC 60751 B +/- 0.3 °C
Order-Information	
TSG-Order-Number:	8006 1105
Conrad-Order-Number:	50 77 74-XX

Dimensions

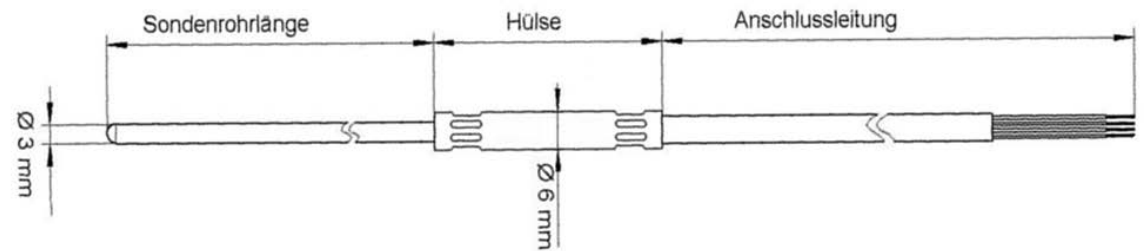

Picture



example of installation

