

Cable Probe Type 04 NiCr-Ni Type K


Product-Data

Sensor element:	Type K (NiCr-Ni) Class 1
Temperature range:	-200...+ 1200 °C
Installation length:	100 mm
Diameter Installation length:	1.5 mm
Probe tube material:	Inconel (2.4860)
Sleeve:	6 x 40 mm 1.4305 bzw. CuZn nickel-plated
Connecting cable:	PVC Compensating line Ø 4 mm / 2 x 0,22 mm ²
Connecting cable length:	2 meters
Tmax connecting cable:	+150 °C
Plug:	open wire ends
Ingress protection EN 60529:	IP 42 transition probe tube to connecting cable
Accuracy:	Class 1 DIN IEC 70584 +/- 1.5 °C

Order-Information

TSG-Order-Number:	8006 1106
Conrad-Order-Number:	50 77 75-XX

Dimensions

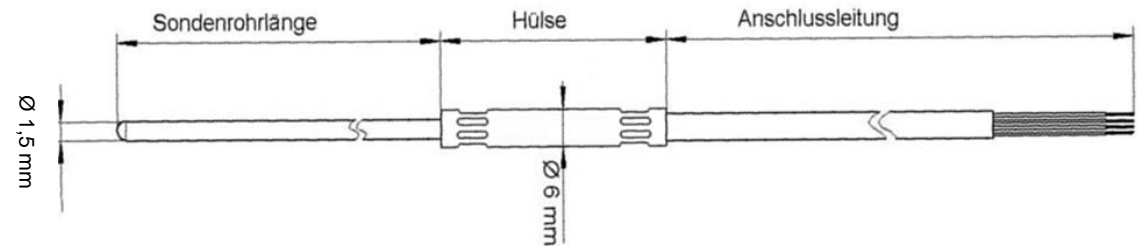

Picture



example of installation

