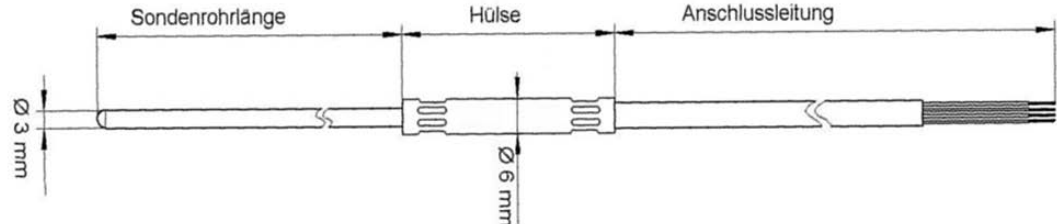


## Cable Probe Type 04 NiCr-Ni Type K

Product-Data	
Sensor element:	Type K (NiCr-Ni) Class 1
Temperature range:	-200...+ 1200 °C
Installation length:	100 mm
Diameter Installation length:	3 mm
Probe tube material:	Inconel (2.4860)
Sleeve:	6 x 40 mm 1.4305 bzw. CuZn nickel-plated
Connecting cable:	PVC Compensating line Ø 4 mm / 2 x 0,22 mm <sup>2</sup>
Connecting cable length:	2 meters
Tmax connecting cable:	+150 °C
Plug:	Open wire ends
Ingress protection EN 60529:	IP 42
Accuracy:	Klasse 1 DIN IEC 70584 +/- 1.5 °C
Order-Information	
TSG-Order-Number:	8006 1107
Conrad-Order-Number:	50 77 78-XX

Dimensions	
	
Picture	example of installation
