

Sheathed thermocouple probe Type 09 NiCr-Ni


Product-Data

Sensor element:	Type K NiCr-Ni Class 1
Temperature range	-200 °C...+1000 °C
Installation length:	100 mm
Diameter Installation length:	3 mm
Probe tube material:	Inconel (2.4860)
Plug:	Miniature TC connector NiCr-Ni Type K
Accuracy:	Class 1 DIN IEC 60584 +/- 1.5 °C

Order-Information

TSG-Order-Number:	8006 1613
Conrad-Order-Number:	50 77 86-XX

Dimensions

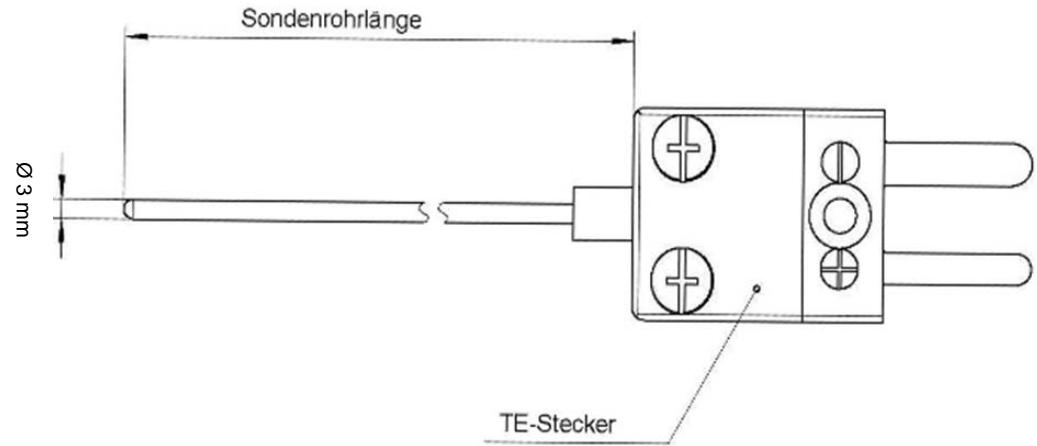

Picture



example of installation

