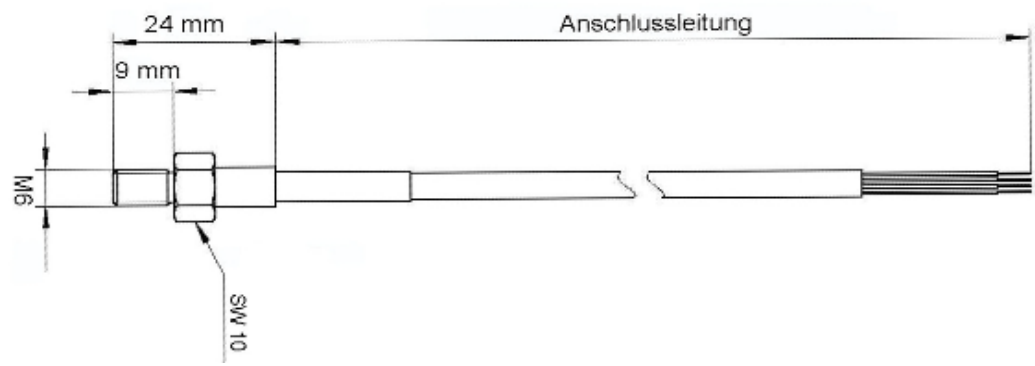


Screwed Probe Type 14 Pt 100 pressure tight to 500 bar

Product-Data	
Sensor element:	Pt 100 Class B
Temperature range	-50...+80 °C
Installation length:	9 mm
Diameter Installation length	6 mm
Probe tube material	1.4305
Process Connecting:	M6 / SW 10
Connecting cable:	PVC insulated Ø 4.5 mm / 4 x 0.14 mm ²
Connecting cable length:	2 meters
Tmax connecting cable	+80 °C
Plug	Open wire ends
Ingress protection EN 60529:	IP 42
Accuracy:	Class B DIN IEC 60751 +/- 0.3 °C
Bestell-Information	
TSG-Order-Number:	8006 1221
Conrad-Order-Number	50 77 95-XX

Dimensions	
	
Picture	example of installation
