



## Screw-on surface T/C Probe (metal ring) Type 15 NiCr-Ni Type K

Product-Data	
Sensor element:	Type K NiCr-Ni Class 1
Temperature range:	-200...+400 °C
Installation length:	8 mm
Diameter Installation length:	1,5 mm
Metal ring material:	1.4305
Connecting cable:	Insulated glass fibre thermocouple
Connecting cable length:	2 meters
Tmax connecting cable:	+400 °C
Plug:	Open wire ends
Accuracy:	Class 1 DIN IEC 70584 +/- 1.5 °C
Order-Information	
TSG-Order-Number:	8006 1322
Conrad-Order-Number:	50 77 96-XX

Dimensions

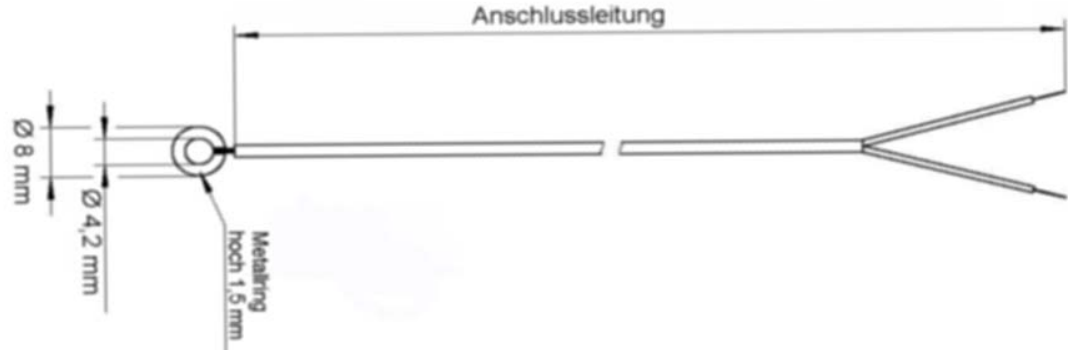

Picture



example of installation

