


Air duct temperature Probe Type 23 Pt 100

Product-Data	
Sensor element:	Pt 100 Class B
Temperature range:	-50...+400 °C
Installation length:	200 mm
Diameter Installation length:	6 mm
Probe tube material:	Stainless steel 1.4571 / 1.4403
Connecting cable:	PVC insulated Ø 4.5 mm / 4 x 0.14 mm ²
Connecting cable length:	2 meters
Tmax connecting cable	+80 °C
Plug:	open wire ends
Accuracy:	Class B DIN IEC 60751 +/- 0.3 °C
Order-Information	
TSG-Order-Number:	8006 1529
Conrad-Order-Number:	50 78 04-XX

Dimensions

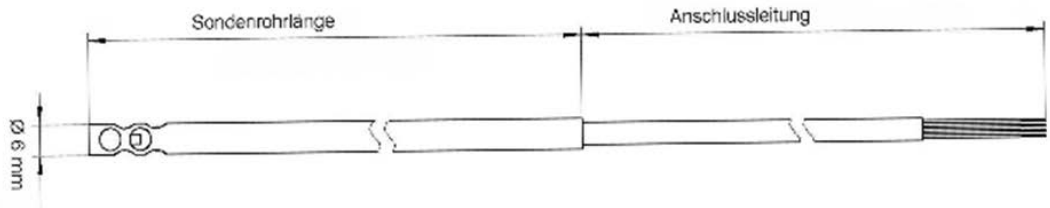

Picture

example of installation

