


PRODUCT SPECIFICATIONS

Description:	Switching Mode Regulated Adaptor
Model No.:	SMP-65W12
Primary Voltage and Frequency:	100-240V AC 50/60Hz 1.8A
Output:	12VDC 5A \pm 10%;
AC Input:	Detachable 1.2M cord type with EU plug (two pins)
DC Plug:	0.3M of cable with cigarette lighter plug
Case color:	Black
Dimension:	117.5mm (L) x 51.5mm(W) x 33.5mm(H) \pm 0.5mm (not including AC power cord & plug)
Weight:	239g (not including power cord)
Operating temperature:	0 °C to 35 °C
Operating humidity:	10% to 85%
Storage temperature:	-10 °C to 55 °C
Storage humidity:	5% to 95%

TESTING CIRCUIT ON OUTPUT:

A = Amperemeter
V = Voltmeter
R = Variable resistor

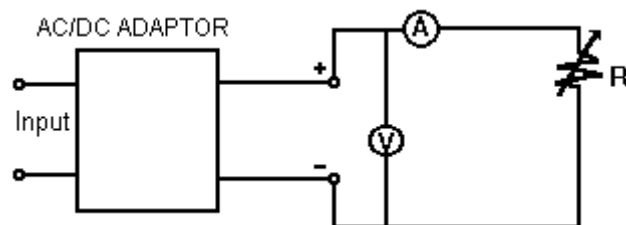

Test method according to standard of EN60950

Plastic Enclosure Material

Polycarbonate resin type no.: 6485(f1) UL File: E41613 from Bayer AG or other equivalent.

VOLTCRAFT®

SPS12-60W

distributed by

Conrad Electronic SE
Klaus-Conrad-Str. 1
D-92240 Hirschau

Model No.: SMP-65W12
PRI.: 100 - 240 V ~ 50/60 Hz 1.8 A
SEC.: 12 V $\overline{\text{---}}$ 5 A 60 VA max.

For office equipment use.
The socket-outlet shall be installed
near equipment and shall be easily
accessible.

