



SITOP UPS501S EXPANSION MODULE 5 KWS FOR
UPS500S (2.5 KWS, 5 KWS) DEGREE OF PROTECTION
IP20

Technical specifications

Input

Mains buffering

Type of energy storage	with capacitors
Energy content / of energy storage	5 kW-s

Output

Efficiency

Protection and monitoring

Signaling

Interface

Product component / PC interface	No
Design of the interface	without

Safety

Verification of suitability / UL-registration	Yes
Verification of suitability / CE mark	Yes
Protection class IP	IP20

EMC


Operating data

Ambient temperature / in operation	0 ... 60 °C
Ambient temperature / on transport	-40 ... +70 °C

Ambient temperature / in storage	-40 ... +70 °C
Mechanics	
Design of the electrical connection	screw-type terminals
Width / of the housing	70 mm
Height / of the housing	125 mm
Depth / of the housing	125 mm
Installation width	70 mm
Required spacing / top	50 mm
Required spacing / bottom	50 mm
Required spacing / left	0 mm
Required spacing / right	0 mm
Net weight	0.7 kg

Product feature / of the housing / housing for side-by-side mounting

Yes

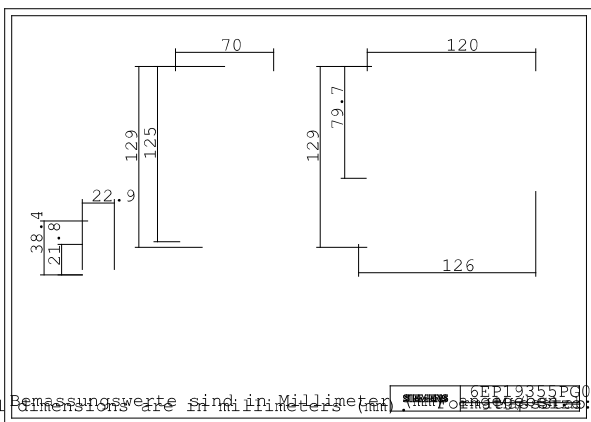

letzte Änderung:

Sep 10, 2012