

# Setpoint adjuster - EMG 30-SP- 4K7LIN - 2940252

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Setpoint value potentiometer, to set setpoints individually, resistance value 4,7 kΩ

The illustration shows version EMG 30-SP- 1K LIN

## Product Features

- For direct setpoint definition in combination with a constant voltage source



## Key commercial data

package_quantity	10
GTIN	4017918079956

## Technical data

### Dimensions

Width	30 mm
Height	75 mm
Depth	68 mm

### Ambient conditions

Ambient temperature (operation)	0 °C ... 40 °C
---------------------------------	----------------

### Input data

Potentiometer	4.7 kΩ
Resistance tolerance	±20 %
Potentiometer, current-carrying capacity	1 W

### Connection data

Conductor cross section solid min.	0.2 mm <sup>2</sup>
Conductor cross section solid max.	4 mm <sup>2</sup>
Conductor cross section stranded min.	0.2 mm <sup>2</sup>
Conductor cross section stranded max.	2.5 mm <sup>2</sup>
Conductor cross section AWG/kcmil min.	24
Conductor cross section AWG/kcmil max	14
Stripping length	8 mm

# Setpoint adjuster - EMG 30-SP- 4K7LIN - 2940252

## Technical data

### Connection data

<b>Screw thread</b>	M3
<b>Connection method</b>	Screw connection

### General

<b>Mounting position</b>	Any
<b>Housing material</b>	Polycarbonate fiber reinforced PC-F
<b>Color</b>	green

## classifications

### eCl@ss

<b>eCl@ss 4.0</b>	27200303
<b>eCl@ss 4.1</b>	27200303
<b>eCl@ss 5.0</b>	27200303
<b>eCl@ss 5.1</b>	27200303
<b>eCl@ss 6.0</b>	27200303
<b>eCl@ss 7.0</b>	27142316
<b>eCl@ss 8.0</b>	27142316

### ETIM

<b>ETIM 2.0</b>	EC001440
<b>ETIM 3.0</b>	EC001440
<b>ETIM 4.0</b>	EC001440
<b>ETIM 5.0</b>	EC001440

 
### UNSPSC

<b>UNSPSC 6.01</b>	30211506
<b>UNSPSC 7.0901</b>	39121008
<b>UNSPSC 11</b>	39121008
<b>UNSPSC 12.01</b>	39121008
<b>UNSPSC 13.2</b>	39121008

## approvals

GOST /


### Approval details



## Drawings

# Setpoint adjuster - EMG 30-SP- 4K7LIN - 2940252

Dimensioned drawing

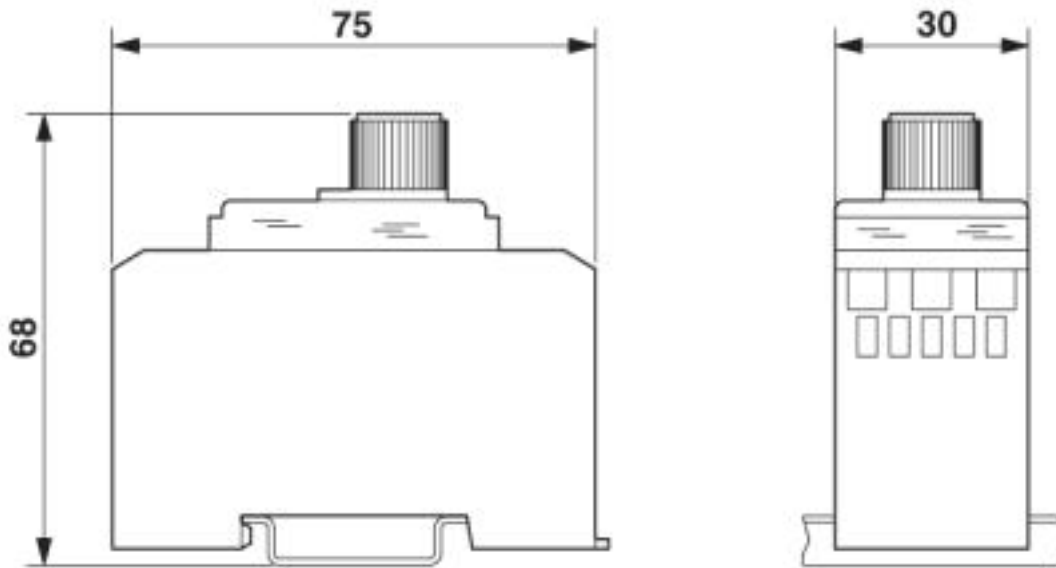

Circuit diagram

