


**4-CONDUCTOR DEVICE
CONNECTORS FOR FIXING SCREW
AND NUT 3 MM Ø OR FOR SELF
TAPPING SREW 2.9 MM Ø FROM TOP**

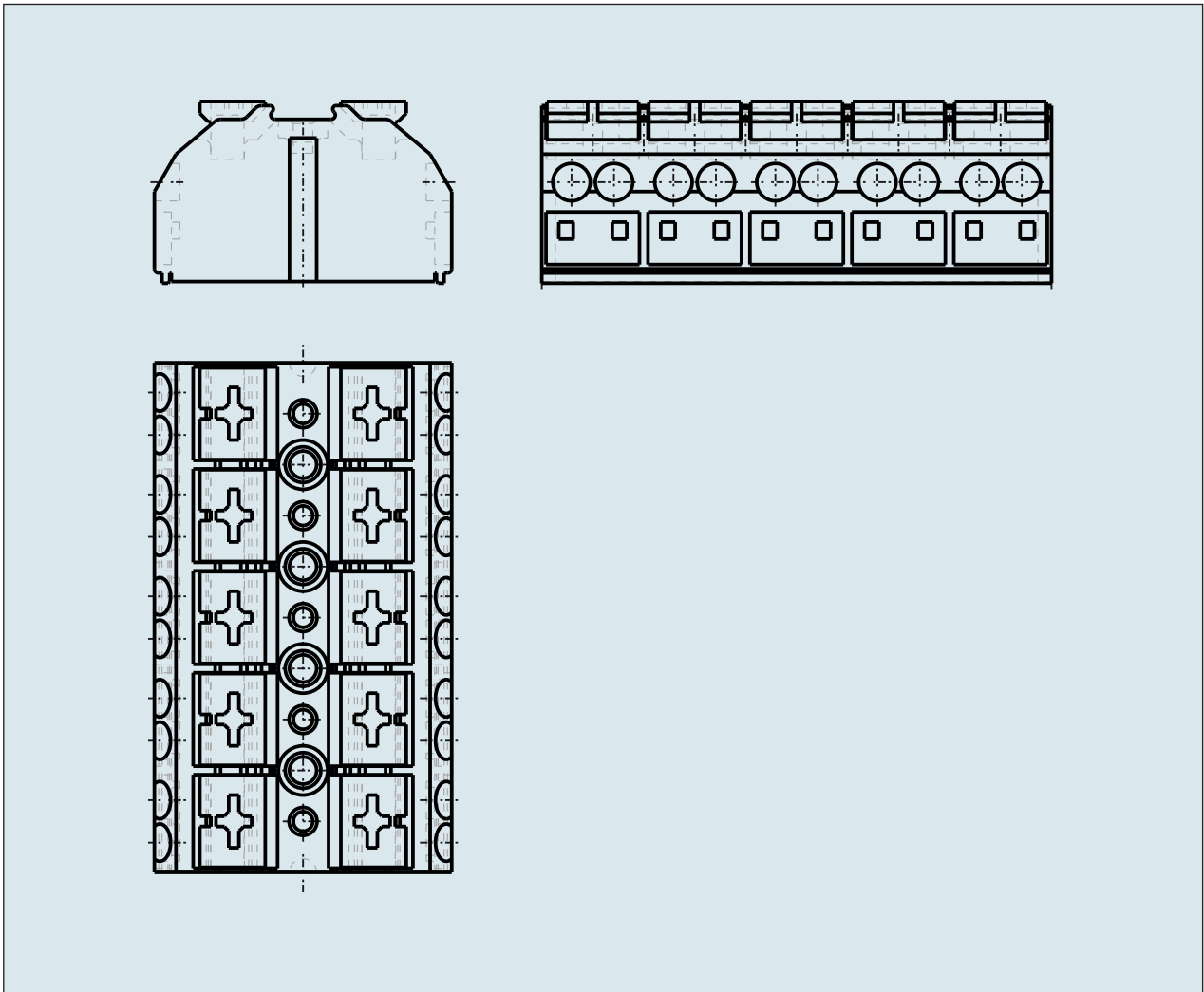

**4-CONDUCTOR DEVICE
CONNECTORS FOR FIXING SCREW
AND NUT 3 MM Ø OR FOR SELF
TAPPING SREW 2.9 MM Ø FROM TOP
5 POLE
862-505 TO 862-2605**

| | |
|---|-----------------|
| ITEM-NO. (ITEM-NO.) | 862-1505 |
| Cross section1 (Cross section / mm²) | 0.5 - 4 |
| Cross section2 (Cross section / AWG) | 20 - 12 |
| Strip length (Strip length / mm) | 10 - 11 |
| Measured voltage (Measured voltage / V) | 500 |
| Measured shock voltage (Measured shock voltage / kV) | 6 |
| Pollution degree (Pollution degree) | 3 |
| Current intensity (Current intensity / A) | 32 |
| P (NO. OF POLES) | 5 |
| Height (Height / mm) | 21.4 |
| Width (Width / mm) | 60 |
| Depth (Depth / mm) | 35 |
| No. of connection Points (No. of connection Points) | 20 |
| No. of potentials (No. of potentials) | 5 |
| COLOR (COLOR) | schwarz |
| Comment (Comment) | ERDE-N-L1-L2-L3 |