


R3-24

PCB MOUNT

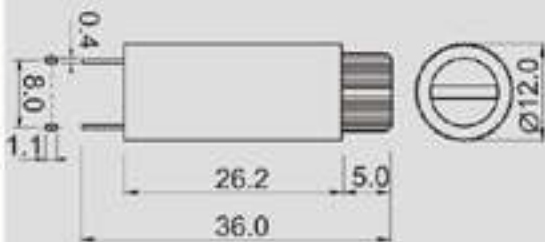

T (1.1mm) 0.428"
PC

10A 250V AC

0.5~4mm

FEATURES:

- Material:
Frame and cap: phenolic(UL flame: 94V-1).
Terminal: nickel plated brass.
- PC terminal mounted.

CAP

Bayonet type

FUSE

∅ 5.0*20 mm