


Product Description

Reliable bending and anti-kink protection; Cable conservation; Functional reliability; To protect flexible cables

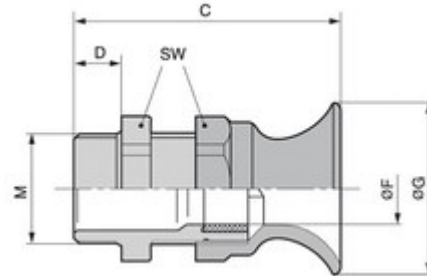

Application range

- Cables for electrical appliances and machinery that are moved under normal use must be protected against excessive bending as required in accordance with VDE 0730.
- Handheld device
- Apparatus construction
- Light and sound applications
- Moving machine parts

Benefits

- Reliable bending and anti-kink protection
- Cable conservation
- Functional reliability
- To protect flexible cables

Design

- Metric connection thread acc. to EN 50262

Note

- Refer to SKINTOP® PG accessories for suitable accessories
- Counter nut to be used: SKINTOP® GMP-GL-M



Technical Data

Caution

Refer to Appendix T21 for the installation dimensions and torques

Colour delivered

Silver grey (RAL 7001)

Material

Body: Polyamide Seal: CR

Protection rating

IP 68 - 5 bar

Temperature range

-20°C to +100°C

Article List

Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length/ D (mm)	Pieces / PU
SKINTOP® BT-M						
53017420	16 x 1,5	3,5-8	19	45.0	12.0	100
53017430	20 x 1,5	5-12	24	54.0	13.0	50
53017440	25 x 1,5	9-14	27	57.0	13.0	50

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.