


SILVYN® LGF-2-M

SILVYN® LGS-2-M

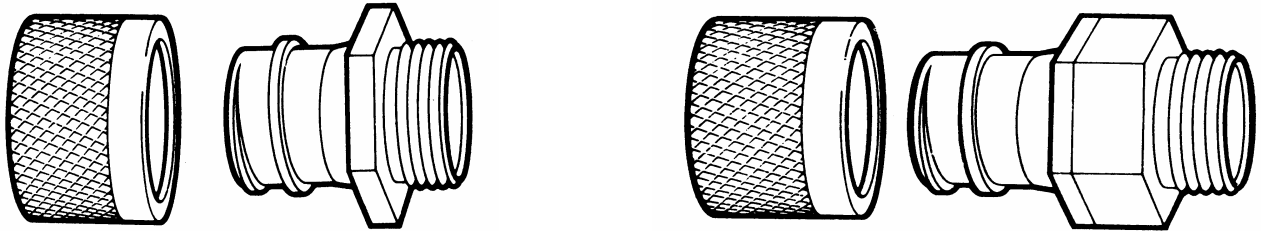

size	wrench size		thread length		total length		hole size	
	LGF 2 M	LGS 2 M	LGF 2 M	LGS 2 M	LGF 2 M	LGS 2 M	LGF 2 M	LGS 2 M
M12x1,5	13	13	8,0	8,0	21,0	30,2	5,6	5,6
M16x1,5	17	17	8,0	8,0	23,0	32,2	8,5	8,5
M16x1,5	19	22	10,0	10,0	25,0	34,2	11,5	11,5
M20x1,5	22	22	10,0	10,0	25,0	34,2	11,5	11,5
M20x1,5	24	24	10,0	10,0	26,3	35,5	15,3	15,3
M25x1,5	29	29	12,0	12,0	32,5	43,7	19,1	19,1
M32x1,5	38	38	13,0	13,0	36,8	48,0	26,2	26,2
M40x1,5	48	48	14,0	14,0	39,0	51,2	34,2	34,2
M50x1,5	58	58	15,0	15,0	42,0	54,2	44,8	44,8
M63x1,5	70	70	18,0	18,0	50,0	63,2	54,5	54,5
M75x1,5	84	84	20,0	20,0	60,0	74,2	66,5	66,5

material : nickel plated brass

application: metal conduit SILVYN® LCC-2

classification: SILVYN® LGF-M 16 (or LGS-M 16) fits to SILVYN® LCC-2/ 16
SILVYN® LGF-M 20 (or LGS-M 20) fits to SILVYN® LCC-2/ 20, etc.

construction: SILVYN® LGF-M fixed metal conduit
SILVYN® LGS-M swivel metal conduit