


## Product Description

Maximum reliability; Optimum strain relief; Wide, variable clamping ranges

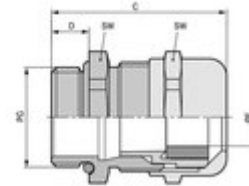

## Application range

- In areas where mechanical and chemical stability are critical
- Chemical industry
- Measurement and control technology
- Machine and equipment manufacturing
- Plant engineering

## Benefits

- Maximum reliability
- Optimum strain relief
- Wide, variable clamping ranges

## Design

- PG connection thread

## Note

- Counter nut to be used: SKINDICHT® SM
- Refer to SKINTOP® PG accessories for suitable accessories



Technical Data

Caution

Refer to Appendix T21 for the installation dimensions and torques

Material

Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR

Protection rating

IP 68 - 5 bar

Temperature range

-30°C to +100°C

Article List

Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length/ D (mm)	Pieces / PU
SKINTOP® MS						
52015700	MS 7	2 - 6,5	14	25.0	5.0	100
52015710	MS 9	4 - 8	17	29.0	6.0	100
52015720	MS 11	4 - 10	20	32.0	6.0	50
52015730	MS 13,5	5 - 12	22	34.0	6.5	50
52015740	MS 16	8 - 14	24	35.0	6.5	50
52015750	MS 21	11 - 18	30	40.0	7.0	25
52015760	MS 29	16 - 25	40	48.0	8.0	25
52015765	MS 36	19 - 32	50	62.0	15.0	10
52015766	MS 42	28 - 38	57	62.0	15.0	5
52015767	MS 48	34 - 44	64	62.0	15.0	5

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.