


Units:mm

# Jump Wires

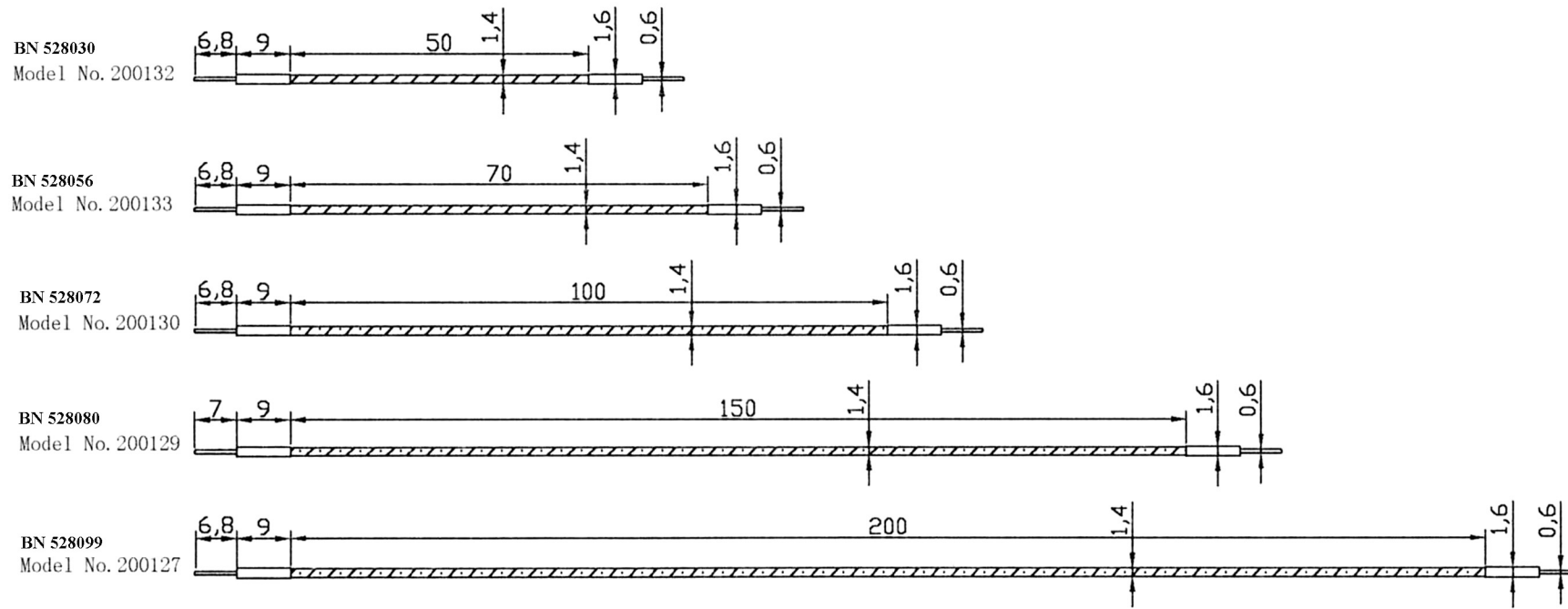

Best No.	Model No.	Product
528030	200132	JUMP WIRES 50mm LONG, COLOR: BROWN (咖啡色)
528056	200133	JUMP WIRES 70mm LONG, COLOR: GREY (灰色)
528072	200130	JUMP WIRES 100mm LONG, COLOR: ORANGE (橘色)
528080	200129	JUMP WIRES 150mm LONG, COLOR: PURPLE (紫色)
528099	200127	JUMP WIRES 200mm LONG, COLOR: BLUE (蓝色)

Character
E209522 UL AWM STYLE 1007 24AWG 80°C 300V VW-1
UNITY LL208655 CSA AWM I A/B 80°C 300V FT1

SPEC		
Insulation	Material	PVC
	Average thickness	0.38mm
	Minimum thickness	0.33mm
Wire	Area	0.205mm <sup>2</sup>
	Minimum area	0.201mm <sup>2</sup>
	Resistance	89.4 Ω/Km

Temperature	80°C
MAX Voltage	300V

Drawing	Rock
Data	December 1, 2011