



Impedance	75Ω
Frequency range	0 to 4.0 GHz
VSWR (straight connectors)	< 1.23 typ
Insulation resistance	≥ 10 <sup>4</sup> MΩ
Center contact resistance	≤ 10.0 mΩ
Outer contact resistance	≤ 7.5mΩ
Test voltage	1000V rms
Working voltage	330V rms
RF-leakage(dB)	> 90 dB

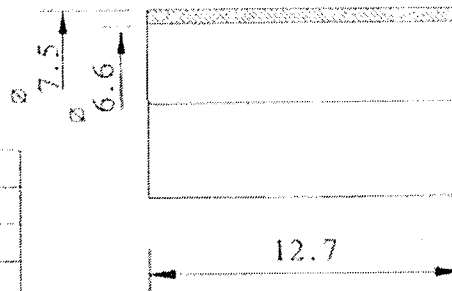

Mounting holes

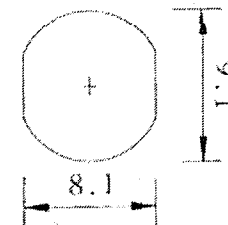

6	Nut	Brass	Nickel
5	Ferrule	Brass	Nickel
4	Washer	Brass	Nickel
3	Insulator	Teflon	White
2	Contact	PH/Bronze	Gold
1	Body	Brass	Gold/Nickel
NO	Description	Material	Finish

DIMENSIONS ARE IN MILLIMETERS

530266

RoHS COMPLIANT

UNLESS OTHERWISE SPECIFIED

TOLERANCES  
 0.5-6=±0.2  
 6-30=±0.4  
 30-120=±0.6  
 120-315=±1.0  
 315-1000=±1.6  
 1000-2000=±2.4

PART NO.

0415202

TITLE: 1.6/5.6 CRIMP JACK FOR RG59/U, RG62/U  
 CABLE

DATE

January / 21 / 2008

NOT SCALED DRAWING

DRAWING NO.

EE208CU-GNGT75