


# AGL TYPE

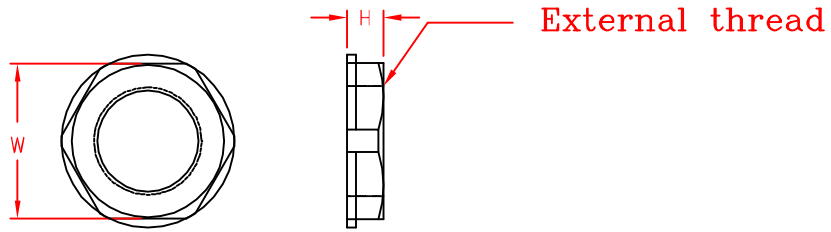

ITEM NO.	External thread	W	H
AGL-12	M12x1.25	17	5.2
AGL-12L	M12x1.5	17	5.2
AGL-16	M16x1.5	21.8	5
AGL-20S	M20x1.5	26.6	6
AGL-20	M20x1.5	26.6	6
AGL-25	M25x1.5	33	7
AGL-32	M32x1.5	41.7	8
AGL-40	M40x1.5	48.3	9
AGL-50	M50x1.5	58.8	9.8
AGL-63	M61x1.5	66	10.8
AGL-63M	M63x1.5	73	11.0
AGL-63L	M63x1.5	73	11.0
AGL-16F	PF20	26.2	6.6
AGL-20F	PF20	26.2	6.6

MATERIAL: UL 94V-2  
 NYLON 66

ITEM NO.

AGL TYPE

SCALE

FINISH

NAME

LOCK NUT



(. .)

TOLERANCE ±0.5mm



(. .)  
 06-05-2008  
 DATE

REVISIONS

K001

R.NO.

