


# EGL TYPE

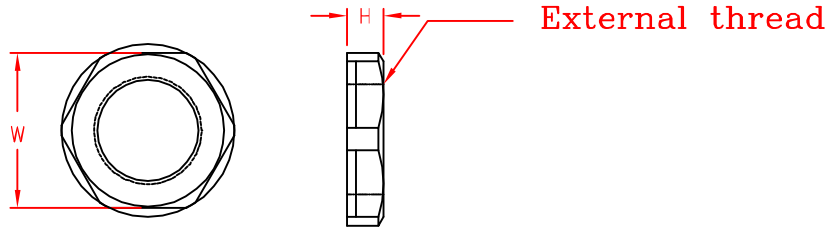

ITEM NO.	External thread	W	H
EGL-7	PG7	18.1	5.1
EGL-7LS	PG7	16.7	5.1
EGL-9	PG9	21	5.1
EGL-9L	PG9	21	5.1
EGL-11	PG11	24	5.1
EGL-11L	PG11	24	5.1
EGL-13.5	PG13.5	27	6.1
EGL-13.5L	PG13.5	27	6.1
EGL-16	PG16	30	6.1
EGL-21	PG21	36	7.1
EGL-29	PG29	46.2	8
EGL-36	PG36	59.2	7.8
EGL-42	PG42	65	7.8
EGL-48	PG48	69.5	7.8

MATERIAL: UL 94V-2  
 NYLON 66

ITEM NO. EGL TYPE

SCALE

FINISH

NAME

LOCK NUT



(. .)

TOLERANCE ±0.5mm



02-02-2007  
 DATE

REVISIONS K001

R.NO.

