



MODELS	PROTECTION	m³/h	l/s	dB(A)*	Pa	W
AXC 100 A	IPX4	195	54	40	350	70
AXC 100 B	IPX4	250	69	45	380	70
AXC 125 A	IPX4	245	60	42	310	70
AXC 125 B	IPX4	325	90	45	340	70
AXC 150 A	IPX4	400	111	46	310	70
AXC 150 B	IPX4	530	147	45	420	80
AXC 160 A	IPX4	440	122	46	330	70
AXC 160 B	IPX4	700	194	47	420	110
AXC 200 A	IPX4	750	208	50	350	80
AXC 200 B	IPX4	980	272	50	580	150
AXC 250	IPX4	1120	311	53	570	170
AXC 315 A	IPX4	1400	389	54	500	150
AXC 315 B	IPX4	1850	514	59	700	300
AXC 355 A	IPX4	2200	611	57	340	240
AXC 355 B	IPX4	2350	653	77	902	650


\*Lp(A) measured at 3m in open field 230V-50Hz.

- High performance centrifugal fans for in-line duct installation.
- Easy and cost-effective solution for a centralized ventilation requirement.


### VERSIONS

2 speed

### INSTALLATION

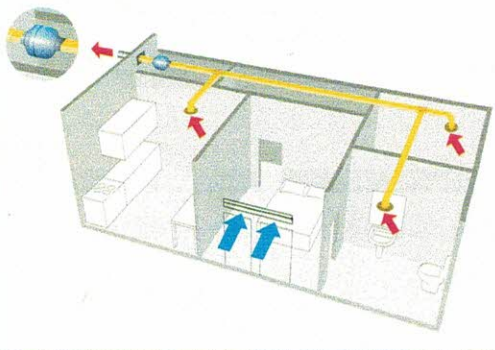

### DIMENSIONS

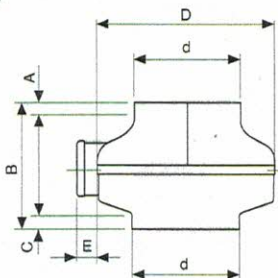

MODELS	A	B	C	ØD	Ød	E	Kg
AXC 100 A	12	215	24	245	98	38	3
AXC 100 B	12	215	24	245	98	38	3
AXC 125 A	11	214	24	245	122	38	3
AXC 125 B	11	214	24	245	122	38	3
AXC 150 A	21	216	23	245	147	38	3
AXC 150 B	22	230	22	333	148	38	5
AXC 160 A	24	215	24	245	157	38	3
AXC 160 B	21	230	22	333	158	38	5
AXC 200 A	22	230	27	333	198	38	5
AXC 200 B	22	230	27	333	198	38	5
AXC 250	22	230	35	333	248	38	5
AXC 315 A	30	297	52	404	314	38	8
AXC 315 B	30	308	52	404	314	38	9
AXC 355 A	44	400	50	484	355	38	12
AXC 355 B	44	400	50	484	355	38	14

### CURVE

