


Product Description

For the benefits, refer to SKINTOP® MS-M

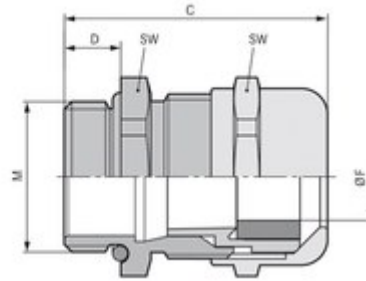

Application range

- With reducing seal insert, to seal cables with smaller outer diameters.

Benefits

- For the benefits, refer to SKINTOP® MS-M

Design

- Metric connection thread acc. to EN 50262

Approvals

- UL File Nr. E79903

Note

- Counter nut to be used: SKINDICHT® SM-M
- Refer to SKINTOP® metric accessories for suitable accessories



Technical Data

Caution

Refer to Appendix T21 for the installation dimensions and torques

Approvals

IP 69 K approval from size M75 x 1.5 pending. UL, CSA, DNV and VDE approval for sizes M90 x 2 to M110 x 2 pending.

Material

Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR

Protection rating

IP 68

IP 69 K

Temperature range

Dynamic: -30 °C to +100 °C

Fixed: -40°C to +100°C

Article List

Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length/ D (mm)	Pieces / PU
SKINTOP® MSR-M						
53112100	12 x 1,5	1-5	16	26,5	6.5	100
53112110	16 x 1,5	2-7	20	32.0	7.0	100
53112120	20 x 1,5	5-10	24	35,5	8.0	50
53112130	25 x 1,5	6-13	29	37,5	8.0	25
53112140	32 x 1,5	7-15	36	42,2	9.0	25
53112150	40 x 1,5	15-23	45	49,5	9.0	10
53112160	50 x 1,5	22-29	54	52.0	10.0	5
53112170	63 x 1,5	28-39	67	61,3	15.0	5
53112511	75 x 1,5	53-63	95	105.0	15.0	1
53112515	110 x 2	76-88	135	154.0	25.0	1

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.