


## Product Description

Especially for thick walls;Maximum reliability;Optimum strain relief;Wide, variable clamping ranges

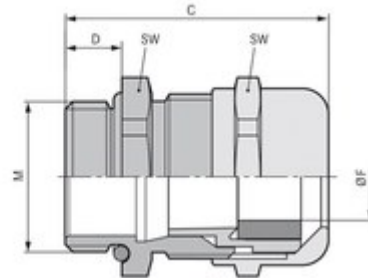

## Application range

- With long connection thread for applications involving a thicker wall.

## Benefits

- Especially for thick walls
- Maximum reliability
- Optimum strain relief
- Wide, variable clamping ranges

## Design

- Metric connection thread acc. to EN 50262

## Approvals

- UL File Nr. E79903

## Note

- Counter nut to be used: SKINDICHT® SM-M
- Refer to SKINTOP® metric accessories for suitable accessories



**Technical Data**

**Caution**

Refer to Appendix T21 for the installation dimensions and torques

**Material**

Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR

**Protection rating**

IP 68 - 10 bar  
IP 69 K

**Temperature range**

Dynamic: -30 °C to +100 °C  
Fixed: -40°C to +100°C

**Article List**

Part number	Article designation / size	Clamping range ØF (mm)	SW (mm)	Overall length/ C (mm)	Thread length/ D (mm)	Pieces / PU
SKINTOP® MS-M-XL						
53112005	12 x 1,5	3-7	16	32,8	12.0	100
53112015	16 x 1,5	4,5-10	20	37.0	12.0	50
53112025	20 x 1,5	7-13	24	39,5	12.0	50
53112035	25 x 1,5	9-17	29	41,5	12.0	25
53112045	32 x 1,5	11-21	36	48,2	15.0	25
53112055	40 x 1,5	19-28	45	53,5	15.0	10
53112065	50 x 1,5	27-35	54	57.0	15.0	5

**Footnote:**

Photographs are not to scale and do not represent detailed images of the respective products.