


C324C104K5R5TA

aka C324C104K5R5TA

Capacitor, ceramic, 0.1 uF, +/-10% Tol, 50V, X7R, Lead Spacing=0.1"

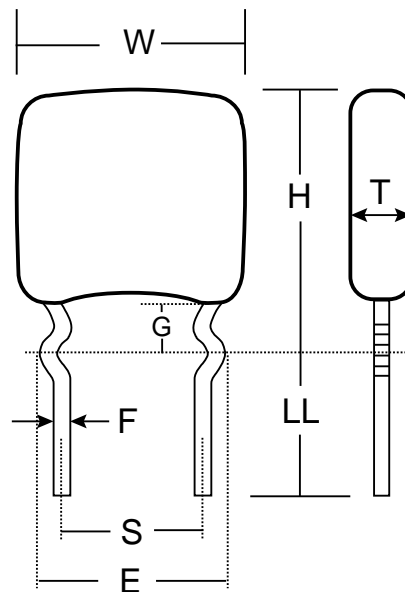

Dimensions (in)

Specifications

ID	Dimension	Tolerance	Manufacturer:	KEMET
W	0.2		Capacitance:	0.1 uF
H	0.26	max	Lead Spacing:	0.1"
T	0.125	max	Voltage:	50V
S	0.1	+/-0.03	Temperature Coefficient:	X7R
LL	0.276	min	Tolerance:	+/-10%
F	0.02	+0.004/-0.001	Body Type:	Radial Conformal
E	0.125	ref	Lead Type:	Standard Leads
G	0.031	ref	Lead Form:	Outward Crimp
			Termination Type:	Tin
			Package Kind:	Bulk
			Package Type:	Bag
			Package Quantity:	500