



**FEMALE PLUG WITH LOCKING  
LEVER PIN SPACING 5 MM / 0.197 IN  
100% PROTECTED AGAINST  
MISMATING WITH RIGHT ANGLED**

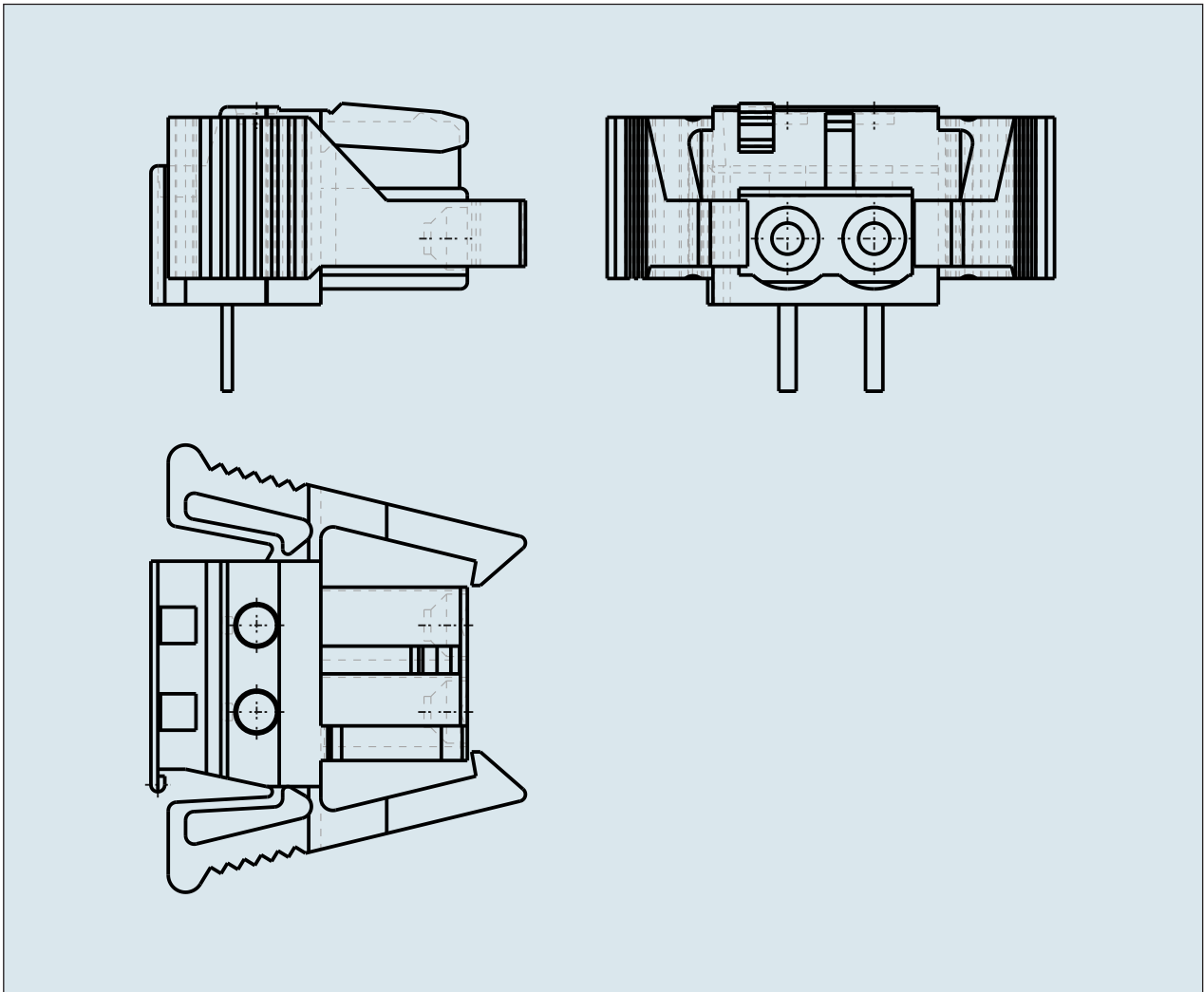

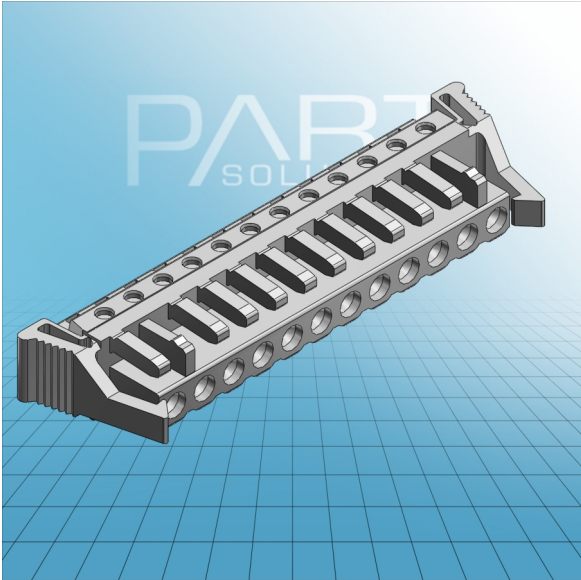

**FEMALE PLUG WITH LOCKING  
LEVER PIN SPACING 5 MM / 0.197 IN  
100% PROTECTED AGAINST  
MISMATING WITH RIGHT ANGLED  
SOLDER PIN**  
722-232/039-000 TO 722-250/039-000

**PDF DATASHEET**

© 1992 - 2011 | CADENAS GmbH

<b>ITEM-NO. (ITEM-NO.)</b>	722-242/039-000
<b>Measured voltage (Measured voltage / V)</b>	320
<b>Measured shock voltage (Measured shock voltage / kV)</b>	4
<b>Pollution degree (Pollution degree)</b>	2
<b>Current intensity (Current intensity / A)</b>	12
<b>RM (PIN SPACING / mm)</b>	5
<b>P (NO. OF POLES)</b>	12
<b>Height (Height / mm)</b>	11.6
<b>Width (Width / mm)</b>	75.8
<b>Depth (Depth / mm)</b>	18.25
<b>COLOR (COLOR)</b>	lichtgrau
<b>Comment (Comment)</b>	L = (No. of poles x Pin Spacing) + 1,5 mm
<b>Dimensions (Dimensions)</b>	1.3 +0.1 mm