
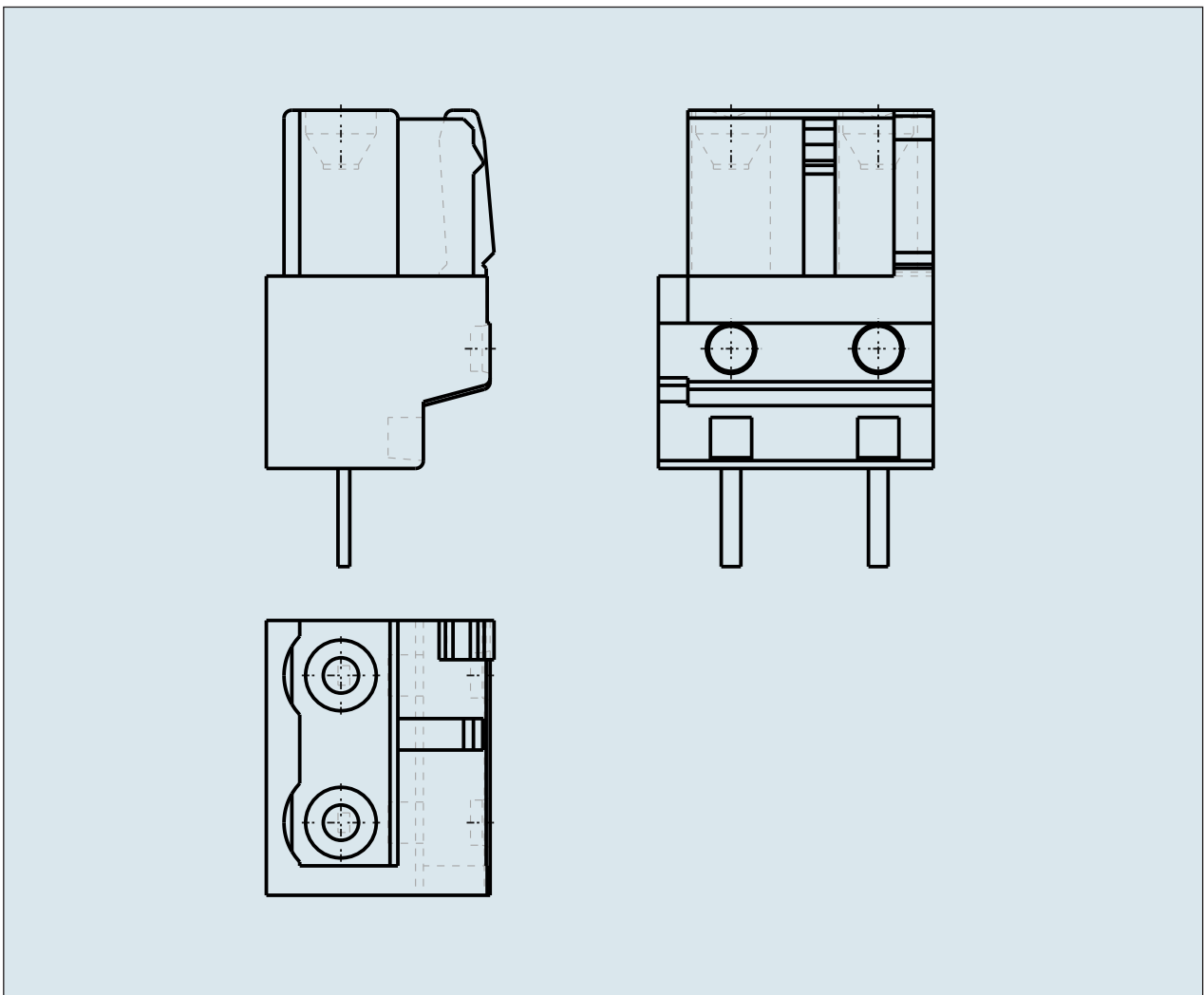


**FEMALE PLUG WITH STRAIGHT
SOLDER PIN PIN SPACING 7.5 MM / 0.
295 IN 100% PROTECTED AGAINST
MISMATING**

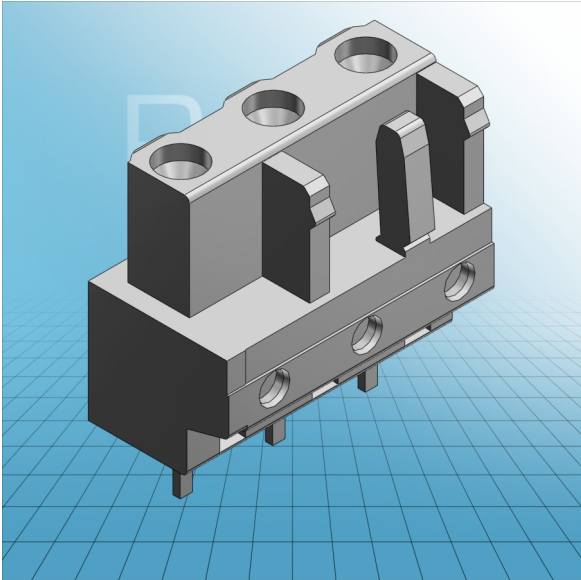

**FEMALE PLUG WITH STRAIGHT
SOLDER PIN PIN SPACING 7.5 MM / 0.
295 IN 100% PROTECTED AGAINST
MISMATING**

722-732 TO 722-746

ITEM-NO. (ITEM-NO.)	722-733
Measured voltage (Measured voltage / V)	630
Measured shock voltage (Measured shock voltage / kV)	6
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	12
RM (PIN SPACING / mm)	7.5
P (NO. OF POLES)	3
Height (Height / mm)	18.25
Width (Width / mm)	21.5
Depth (Depth / mm)	11.6
COLOR (COLOR)	lichtgrau
Comment (Comment)	$L = (\text{No. of poles} - 1) \times \text{Pin Spacing} + 5 \text{ mm} + 1,5 \text{ mm}$
Dimensions (Dimensions)	1.3 +0.1 mm