
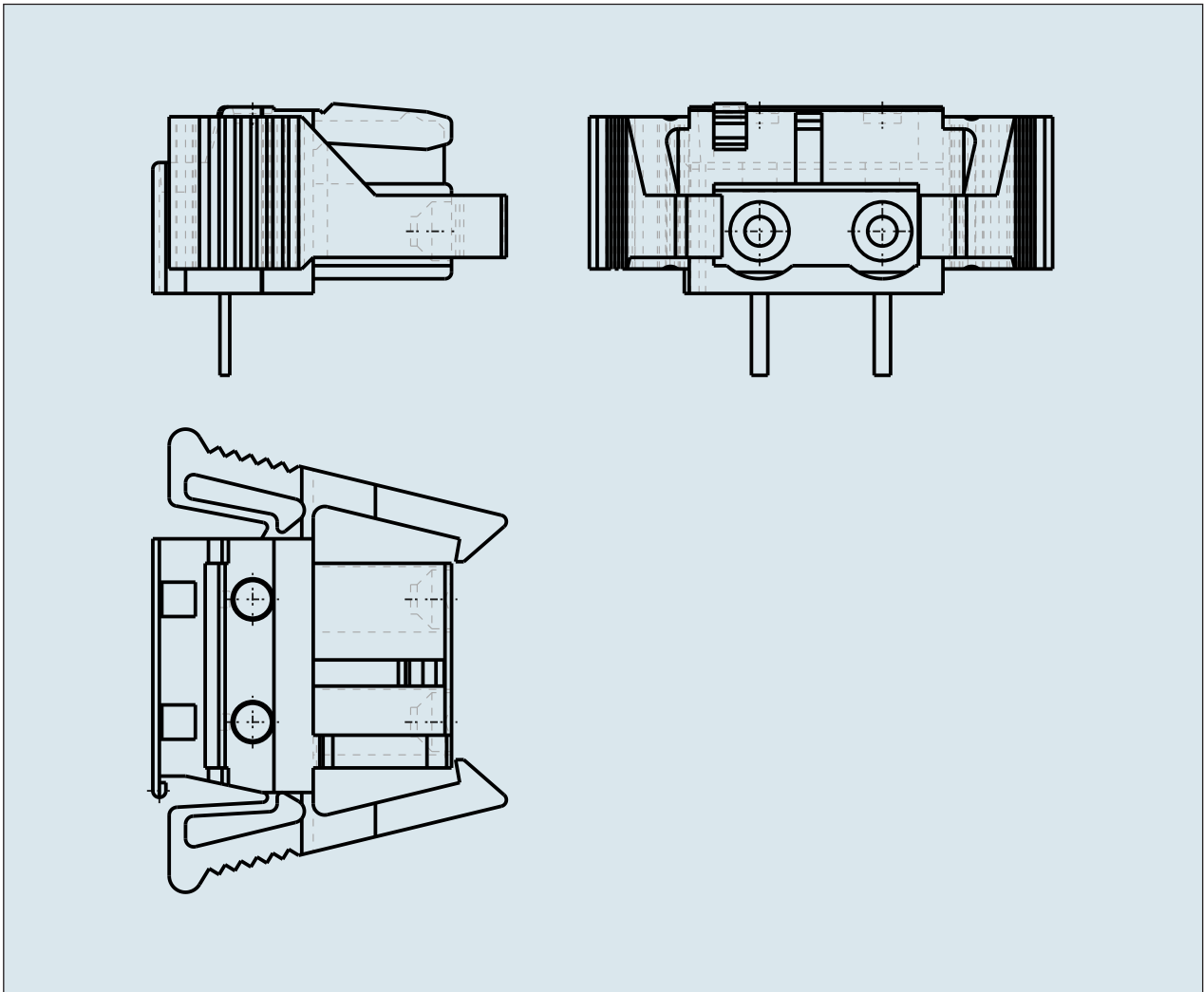


**FEMALE PLUG WITH LOCKING  
LEVER PIN SPACING 7.5 MM / 0.295 IN  
100% PROTECTED AGAINST  
MISMATING WITH RIGHT ANGLED**

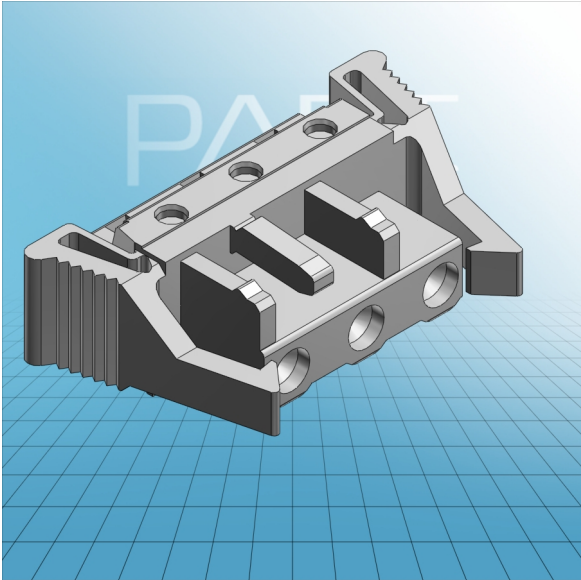

**FEMALE PLUG WITH LOCKING  
LEVER PIN SPACING 7.5 MM / 0.295 IN  
100% PROTECTED AGAINST  
MISMATING WITH RIGHT ANGLED  
SOLDER PIN**  
722-832/039-000 TO 722-842/039-000

ITEM-NO. (ITEM-NO.)	722-833/039-000
Measured voltage (Measured voltage / V)	630
Measured shock voltage (Measured shock voltage / kV)	6
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	12
RM (PIN SPACING / mm)	7.5
P (NO. OF POLES)	3
Height (Height / mm)	11.6
Width (Width / mm)	35.8
Depth (Depth / mm)	18.25
COLOR (COLOR)	lichtgrau
Comment (Comment)	$L = (\text{No. of poles} - 1) \times \text{Pin Spacing} + 5 \text{ mm}$
Dimensions (Dimensions)	1.3 +0.1 mm