
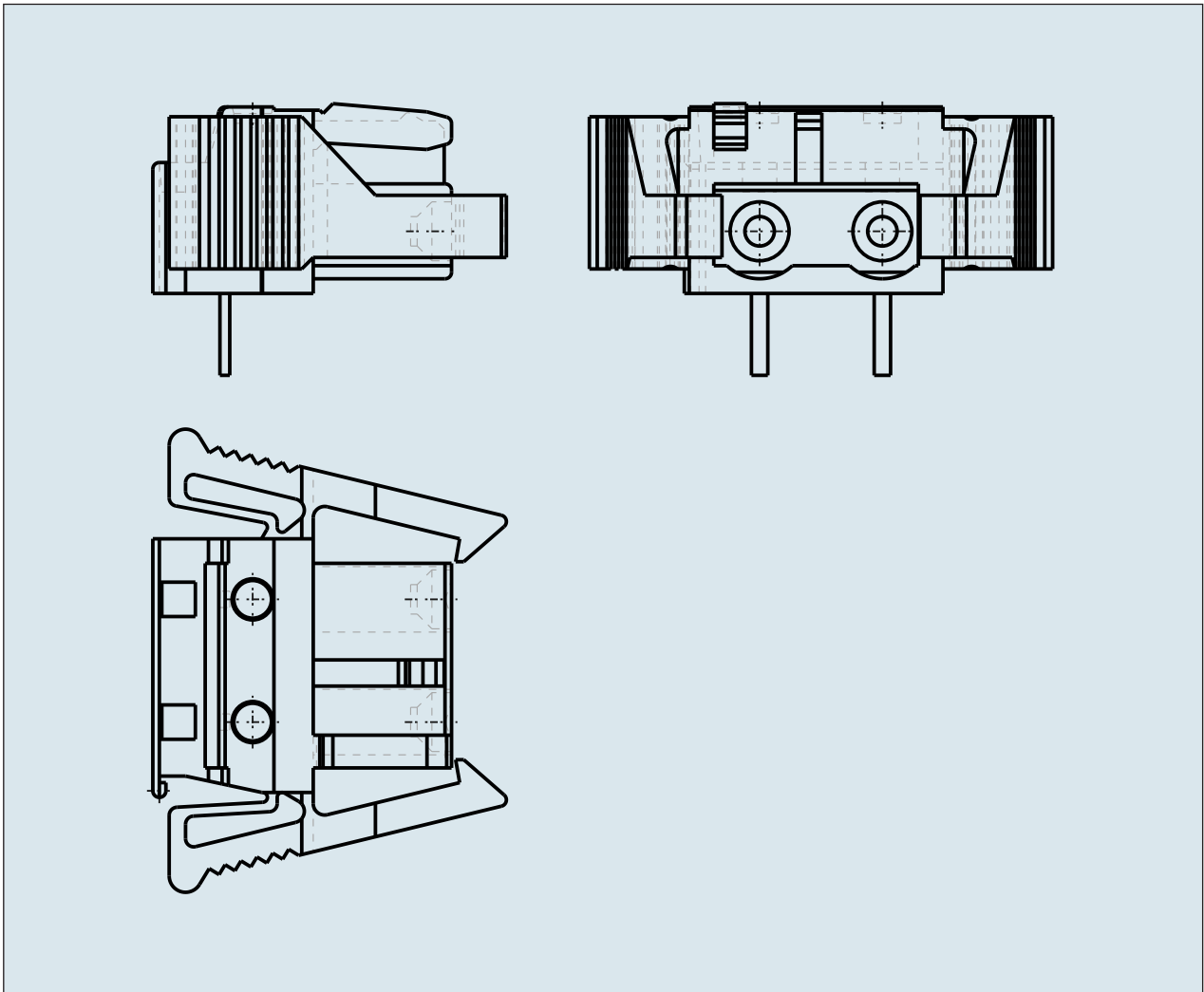


**FEMALE PLUG WITH LOCKING
LEVER PIN SPACING 7.5 MM / 0.295 IN
100% PROTECTED AGAINST
MISMATING WITH RIGHT ANGLED**

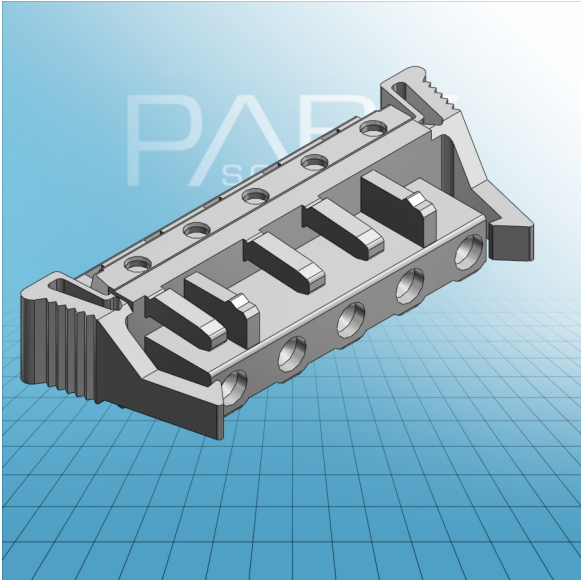

**FEMALE PLUG WITH LOCKING
LEVER PIN SPACING 7.5 MM / 0.295 IN
100% PROTECTED AGAINST
MISMATING WITH RIGHT ANGLED
SOLDER PIN**
722-832/039-000 TO 722-842/039-000

ITEM-NO. (ITEM-NO.)	722-835/039-000
Measured voltage (Measured voltage / V)	630
Measured shock voltage (Measured shock voltage / kV)	6
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	12
RM (PIN SPACING / mm)	7.5
P (NO. OF POLES)	5
Height (Height / mm)	11.6
Width (Width / mm)	50.8
Depth (Depth / mm)	18.25
COLOR (COLOR)	lichtgrau
Comment (Comment)	L = (No. of poles - 1) x Pin Spacing + 5 mm
Dimensions (Dimensions)	1.3 +0.1 mm