




## 2-Piece Fixing Ties with Pipe Clip, twistable 360°

### Features and Benefits


This simple to use inside serrated tie provides the opportunity to attach an additional 5mm diameter cable, pipe or hose to an existing bundle. Offering the facility of a full 360 degrees of rotation, the second bundle can be orientated in any direction in relation to the main harness. Ideally suited for any application where the cable, pipe or hose can move in relation to the fixing point.

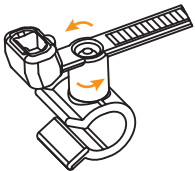

T50SVC65




T50SVC5 rotates in any direction.

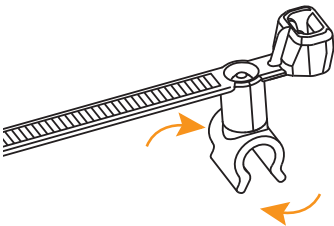

T50SVC5

### Material Data

 Cable Tie	<b>Polyamide 6.6 Heat Stabilised (PA66HS)</b>
Operating Temperature	<b>-40 °C to +105 °C Continuous, (+145 °C for 500 h)</b>
Flammability	<b>UL94 V2</b>



Technical Table

Article-No.	Type	Length (L)	Width (W)	Bundle Ø max.	Min. Tensile strength for ties (N)	Attach to Ø	Material	Colour
156-00318	<b>T50SVC4S</b>	155	4,7	35.0	225	3.8-4.2	PA66HS, PP	Black (BK), Natural (NA)
156-00447	<b>T50SVC4</b>	155	4.7	35.0	225	3.8-4.2	PA66HS, PA66HIRHS	Black (BK)
155-31202	<b>T50SVC5</b>	155	4.7	35.0	225	4.5-5.2	PA66HS	Black (BK)
156-00155	<b>T50SVC65</b>	155	4.7	35.0	225	6.5-8.0	PA66HS, PA66HIRHS	Black (BK)
156-00134	<b>T50SVCOC10-14</b>	155	4.7	35.0	225	10.0-14.0	PA66HS, PA66HIRHS	Black (BK)
156-00135	<b>T50SVCOC15-18</b>	155	4.7	35.0	225	15.0-18.0	PA66HS, PA66HIRHS	Black (BK)
156-00136	<b>T50SVCOC19-245</b>	155	4.7	35.0	225	19.0-24.5	PA66HS, PA66HIRHS	Black (BK)
156-00272	<b>T50SVCOC25-31</b>	155	4.7	35.0	225	25.0-31.0	PA66HS, PA66HIRHS	Black (BK)
156-00273	<b>T50SVCOC31-39</b>	155	4.7	35.0	225	31.0-39.0	PA66HS, PA66HIRHS	Black (BK)
156-00137	<b>T50SVCOC39-45</b>	155	4.7	35.0	225	39.0-45.0	PA66HS, PA66HIRHS	Black (BK)
156-00128	<b>T50SMVCOC10-14</b>	210	4.7	50.0	225	10.0-14.0	PA66HS, PA66HIRHS	Black (BK)
156-00129	<b>T50SMVCOC15-18SET</b>	210	4.7	50.0	225	15.0-18.0	PA66HS, PA66HIRHS	Black (BK)
156-00130	<b>T50SMVCOC19-245</b>	210	4.7	50.0	225	19.0-24.5	PA66HS, PA66HIRHS	Black (BK)
156-00577	<b>T50SMVCOC19245</b>	210	4.7	50.0	225	19.0-24.5	PA46	Grey (GY)
156-00303	<b>T50SMVCOC25-31</b>	210	4.7	50.0	225	25.0-31.0	PA66HS, PA66HIRHS	Black (BK)
156-00304	<b>T50SMVCOC31-39</b>	210	4.7	50.0	225	31.0-39.0	PA66HS, PA66HIRHS	Black (BK)
156-00131	<b>T50SMVCOC39-45SET</b>	210	4.7	50.0	225	39.0-45.0	PA66HS, PA66HIRHS	Black (BK)

All dimensions in mm. Subject to technical changes.