



Self Adhesive Clips

- SAC with flexible flat design
- 130100 for Flat Ribbon Cables

Features and Benefits

The metal 'tongue' of the SAC-series can be bent to suit any shape or configuration of wires or cables. Cost effective with easy application on smooth, clean surfaces.


The self adhesive clip 130100 with integrated clamp can be used for holding flat cables.

Application

These clips are ideal for use in applications which are difficult to access, or for areas where self adhesive is the only possible fixing method (for example 'holes' would be unacceptable). Typically applications include domestic appliances and trailers.



Malleable tongue allows for a variety of sizes per clip.

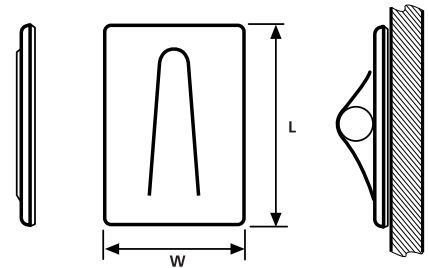

SAC-Series Self Adhesive Clip

Material Data	
Material	Electroplated mild steel (ST)
Adhesive	Acrylate with base of polyethylene foam
Operating Temperature	-40 °C to +70 °C




Technical Table

Article-No.	Type	Length (L)	Width (W)	Bundle Ø max.	Material	Colour	Adhesive
151-00033	SAC0	20.0	15.0	3.0	ST	White (WH)	Acrylate
151-00100	SAC1	30.0	20.0	4.0	ST	White (WH)	Acrylate
151-00200	SAC2	35.0	25.0	8.0	ST	White (WH)	Acrylate
151-00300	SAC3	43.0	31.0	12.0	ST	White (WH)	Acrylate
151-00400	SAC4	51.0	38.0	16.0	ST	White (WH)	Acrylate

All dimensions in mm. Subject to technical changes.

For more information on the types of adhesive please turn to page 162.

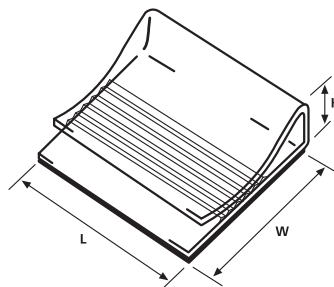

130100 Self Adhesive Clip

Material Data	
Material	Polyvinylchloride (PVC)
Operating Temperature	-25 °C to +65 °C



Technical Table

Article-No.	Type	Length (L)	Width (W)	Height (H)	Material	Colour	Adhesive
154-01119	130100	25.0	25.0	9.1	PVC	White (WH)	Acrylate

All dimensions in mm. Subject to technical changes.