


Technical data sheet

Article number:
169-22750

IWS7.5

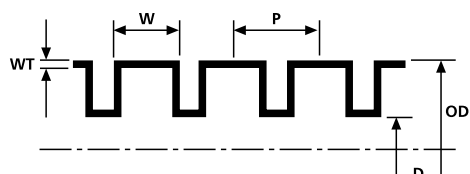

Product Group	Non-Metallic Conduits
Product Family	IWS Polyamide 6
Material	Polyamide 6 (PA6)
Colour	Black (BK)
Bending Radius min. (R)	13 mm
Diameter (D)	6.7 mm
Flammability	UL 94 HB, FMVSS 302
Halogen-free	Yes
Inside Ø (ID)	6.7 mm
Length (L)	50 m
Nominal Ø	7.5 mm
Operating Temperature	-40 °C to +120 °C
Outside Ø (OD)	10.0 mm

HF ✓

RoHS ✓