



Edge protection grommets

Features and Benefits


HellermannTyton edge protection grommets, made of cadmium-free, flexible PVC or Polyethylene, come in a wide range of shapes and sizes. They are resistant to various minerals and environmental effects.

Application


Edge protection grommets are used wherever cable and wires are routed through outlets and apertures. HellermannTyton grommets offer excellent mechanical protection.



HV1201 to HV1218.

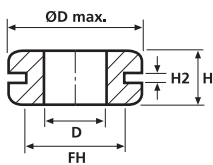


HV1101

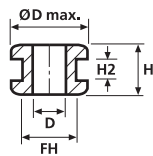


HV1201 to HV1218


Material Data	
Material	Flexible Polyvinyl Chloride, cadmium free (PVC)
Flammability	UL94 V2
Operating Temperature	-30 °C to +60 °C
Shore Hardness A	56±5

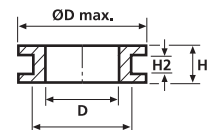


HV1301 to HV1305

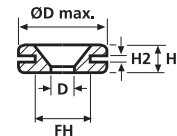




HV1401

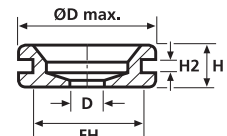

HV1402

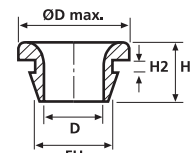

HV1502

 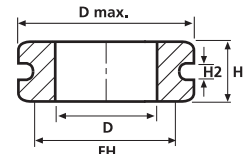 

HV1606 to HV1608

Technical Table

Article-No.	Type	Ø D max.	Fixing Hole Ø (FH)	Ø D	Height (H)	Height (H2)	Colour
633-01010	HV1101	25.5	19.0	12.0	10.0	1.6	Black (BK)
633-02010	HV1201	9.5	6.4	4.0	5.6	1.6	Black (BK)
633-02020	HV1201B	9.5	6.4	4.0	6.5	2.5	Black (BK)
633-02030	HV1203	17.5	12.0	10.0	6.8	2.0	Black (BK)
633-02040	HV1204	17.5	12.0	10.0	8.8	4.0	Black (BK)
633-02050	HV1205	17.5	13.5	10.0	8.7	4.0	Black (BK)
633-02060	HV1206	17.5	12.0	10.0	10.8	6.0	Black (BK)
633-02070	HV1207	14.0	10.0	6.0	6.4	1.5	Black (BK)
633-02080	HV1208	14.0	9.5	8.0	8.0	1.5	Black (BK)
633-02090	HV1209	11.0	9.0	4.0	5.5	1.5	Black (BK)
633-02100	HV1210	15.0	9.0	6.0	10.5	2.0	Black (BK)
633-02120	HV1212	9.0	6.0	4.0	7.0	1.0	Black (BK)
633-02150	HV1215	10.0	8.0	6.0	5.0	1.0	Black (BK)
633-02160	HV1216	14.5	8.0	5.0	6.5	1.5	Black (BK)
633-02180	HV1218	14.0	10.0	6.0	9.0	4.0	Black (BK)
633-03010	HV1301	15.9	11.0	8.0	7.0	1.0	Black (BK)
633-03020	HV1302	15.9	11.0	8.0	9.0	3.0	Black (BK)
633-03030	HV1303	15.9	11.0	8.0	6.4	1.6	Black (BK)
633-03040	HV1304	15.9	11.0	8.0	10.8	6.0	Black (BK)
633-03050	HV1305	24.0	18.0	14.0	7.0	3.0	Black (BK)
633-03059	HV1305	24.0	18.0	14.0	7.0	3.0	White (WH)
633-04010	HV1401	15.9	9.5	5.0	4.8	0.8	Black (BK)
633-04020	HV1402	23.0	18.5	6.0	7.0	2.0	Black (BK)
633-05020	HV1502	11.5	8.0	6.5	8.0	1.5	Black (BK)
633-06068	HV1606	31.0	25.0	17.0	11.0	3.0	Grey (GY)
633-06078	HV1607	43.0	37.0	29.0	11.0	3.0	Grey (GY)
633-06088	HV1608	58.0	52.0	44.0	11.0	3.0	Grey (GY)

All dimensions in mm. Subject to technical changes.