


Data sheet | Item number: 726-541

Matrix patchboard; Marking 1-48; Color of modules: blue; Numbering of modules on sides 1 and 2 arranged vertically and horizontally; suitable for Ex i applications; 48-pole

www.wago.com/726-541

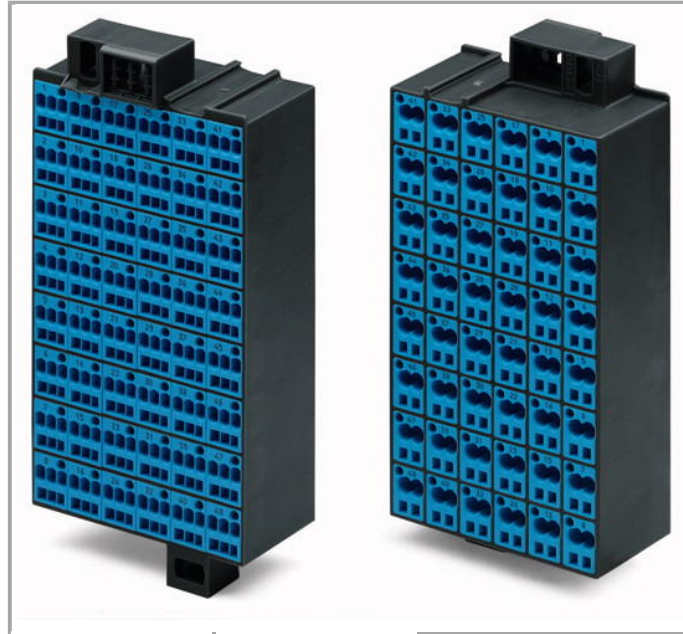

RoHS Compliant

BOMcheck.net

Color: ■

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	10 A
Legend (ratings)	(III / 3) $\hat{=}$ Overvoltage category III / Pollution degree 3

Connection data

Connection type (1)	Side 1
Connection technology	CAGE CLAMP®
Number of connection points (connection type)	3
Actuation type	Operating tool
Connectable conductor materials	Copper Aluminum

Solid conductor	0.08 ... 1.5 mm ² / 28 ... 16 AWG
Fine-stranded conductor	0.08 ... 1.5 mm ² / 28 ... 16 AWG
Strip length	8 ... 10 mm / 0.31 ... 0.39 Inch
Connection type (2)	Side 2
Number of connection points	2
No. of poles	48
Type of wiring	Front-entry wiring

Geometrical Data

Width	65.3 mm / 2.571 inch
Height	132 mm / 5.197 inch
Depth	36.5 mm / 1.437 inch

Mechanical data

Marking	Marking 1-48
---------	--------------

Material Data

Color	dark gray
Fire load	4.24 MJ
Weight	265.47 g

Commercial data

Country of origin	DE
GTIN	4044918980098
Customs Tariff No.	85369010000

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CSA DEKRA Certification B.V.	1101143
	KEMA/KEUR DEKRA Certification B.V.	71-100850

UL-Approvals

Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45172



Compatible products

check



Item no.: 210-137

Test plug; 2.3 mm Ø; with 500 mm cable

www.wago.com/210-137

Insulation stop



Item no.: 726-901

Insulation stop; 0.08 - 0.2 mm² "s" (0.14 mm² "f-st"); 4 x 3 pieces/strip

www.wago.com/726-901



Item no.: 726-906

Insulation stop; 0.25 mm² "s"; 0.14 - 0.25 mm² "f-st"; 4 x 3 pieces/strip

www.wago.com/726-906



Item no.: 726-907

Insulation stop; 0.25 - 0.5 mm² "s+f-st"; 4 x 3 pieces/strip

www.wago.com/726-907

Marking accessories



Item no.: 209-185

Adaptor

www.wago.com/209-185



Item no.: 209-500/209-035

WSB marking card; as card; MARKED; X (100x); not stretchable; Horizontal marking; snap-on type

www.wago.com/209-500/209-035



Item no.: 209-501

WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501



Item no.: 209-501/000-002

WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-002



Item no.: 209-501/000-005

WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-005



Item no.: 209-501/000-006

WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-006



Item no.: 209-501/000-007

WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-007



Item no.: 209-501/000-012

WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-012



Item no.: 209-501/000-017
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-017



Item no.: 209-501/000-023
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-023



Item no.: 209-501/000-024
WSB marking card; as card; not stretchable; plain; snap-on type

www.wago.com/209-501/000-024



Item no.: 209-502
WSB marking card; as card; MARKED; 1 ... 10 (10x); not stretchable; Horizontal marking; snap-on type

www.wago.com/209-502



Item no.: 209-566
WSB marking card; as card; MARKED; 1 ... 50 (2x); not stretchable; Horizontal marking; snap-on type

www.wago.com/209-566



Item no.: 210-612
Marking strips; for self-marking; plain; Self-adhesive

www.wago.com/210-612



Item no.: 726-905
Adaptor

www.wago.com/726-905

General accessories



Item no.: 726-902
Adaptor

www.wago.com/726-902



Item no.: 726-903
Additional module for matrix patchboards; for snap-on fixing to the lower fixing element; Additional module with contact to mounting frame

www.wago.com/726-903



Item no.: 726-904
Additional module for matrix patchboards; for snap-on fixing to the lower fixing element; insulated; Additional module

www.wago.com/726-904

ferrule



Item no.: 216-104
Ferrule; Sleeve for 1.5 mm² / AWG 16; uninsulated; electro-tin plated

www.wago.com/216-104



Item no.: 216-123
Ferrule; Sleeve for 1 mm² / AWG 18; uninsulated; electro-tin plated

www.wago.com/216-123



Item no.: 216-202
Ferrule; Sleeve for 0.75 mm² / AWG 20; insulated; electro-tin plated

www.wago.com/216-202



Item no.: 216-204
Ferrule; Sleeve for 1.5 mm² / AWG 16; insulated; electro-tin plated

www.wago.com/216-204

tools



Item no.: 210-719
Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm

www.wago.com/210-719

Jumper



Item no.: 709-107

Wire commoning chain; insulated; 32 connections

www.wago.com/709-107

Downloads

Documentation

Bid Text

726-541	Oct 18, 2017	DOC 25.6 kB	Download
---------	--------------	----------------	----------

smartDATA

CAD data

3D Download 726-541	URL	Download
---------------------	-----	----------

Subject to changes.