


Data sheet | Item number: 726-903

Additional module for matrix patchboards; for snap-on fixing to the lower fixing element; Additional module with contact to mounting frame

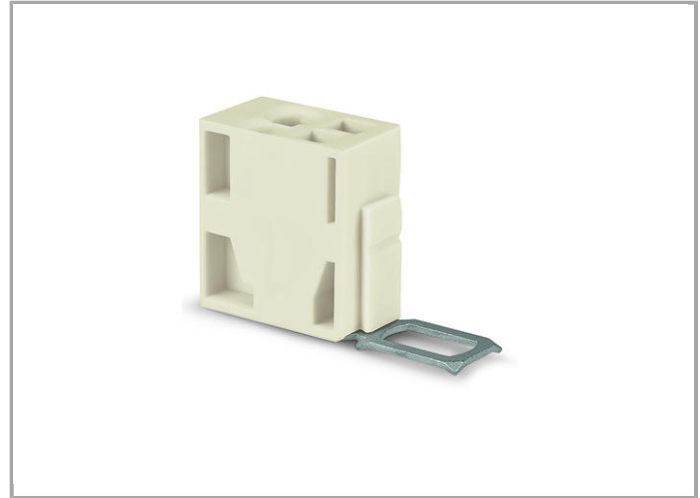


www.wago.com/726-903



RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

Color:

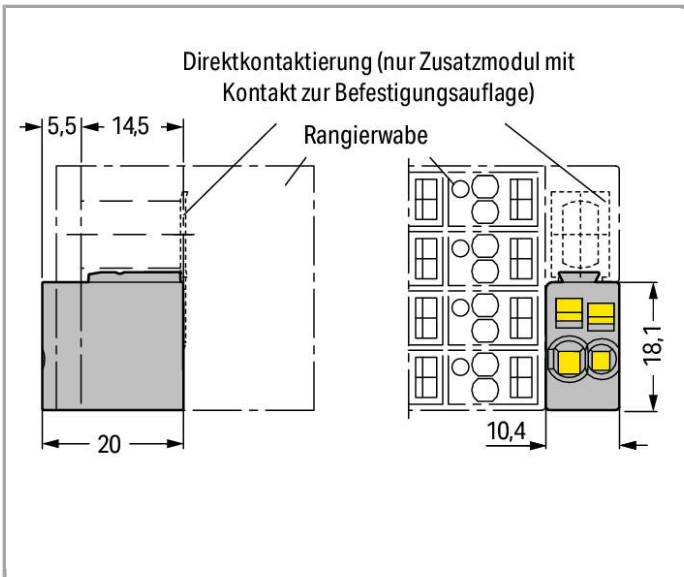

Data
Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	4 kV
Rated current	10 A

Connection data

Connection technology	CAGE CLAMP®
Solid conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 4 mm ² / 28 ... 12 AWG
Strip length	9 mm / 0.35 Inch
Type of wiring	Front-entry wiring

Geometrical Data

Width	10.4 mm / 0.409 inch
Height	18.1 mm / 0.713 inch
Depth	20 mm / 0.787 inch

Material Data

Color	white
Fire load	0.073 MJ
Weight	4.653 g

Commercial data

Country of origin	DE
GTIN	4045454567767
Customs Tariff No.	85369010000

Approvals / Certificates

Country specific Approvals

Logo	Approval	Certificate name
	CSA DEKRA Certification B.V.	1101143
	CSA DEKRA Certification B.V.	1101143
	KEMA/KEUR DEKRA Certification B.V.	71-100850



Downloads

Documentation

Bid Text

726-903	Oct 18, 2017	DOC 23.0 kB	Download
---------	--------------	----------------	----------

Subject to changes.