



Screw Fixing Cable Tie Mounts

• Q-mount Series CTQM


The "2-way" mounting bases CTQM provide a safe guiding of cables and conduits.

- For cable ties up to 5 mm width
- The base is mounted with a screw with countersunk head (max. \varnothing of head: 8.0mm)

The Q-mount offers a perfect solution in combination with the Q-tie cable ties. It keeps the inserted cable tie in place during pre-assembly and ensures that the Q-tie does not slip out even in difficult situations, for example vertical mounting positions.



Q-mount, CTQM 2-way entry, screwable.

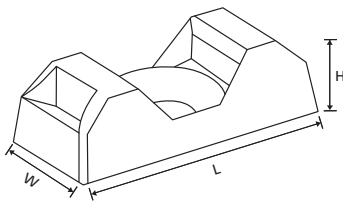

Mounting base CTQM

Material Data	
Material	Polyamide 6.6 (PA66)
Colour	Natural (NA), Black (BK)
Operating Temperature	-40 °C to +105 °C Continuous, (+105 °C for 500 h)
Flammability	UL94 V2



Please find more Q-Series products for your system solution on page 81 and 508.

Technical Table

Article-No.	Type	Length (L)	Width (W)	Height (H)	Fixing Hole \varnothing (FH)	Strap Width max. (G)	Material	Colour
151-10920	CTQM5	21.0	9.5	6.7	4.5	5.0	PA66	Natural (NA)
151-10930	CTQM5	21.0	9.5	6.7	4.5	5.0	PA66	Black (BK)

All dimensions in mm. Subject to technical changes.