
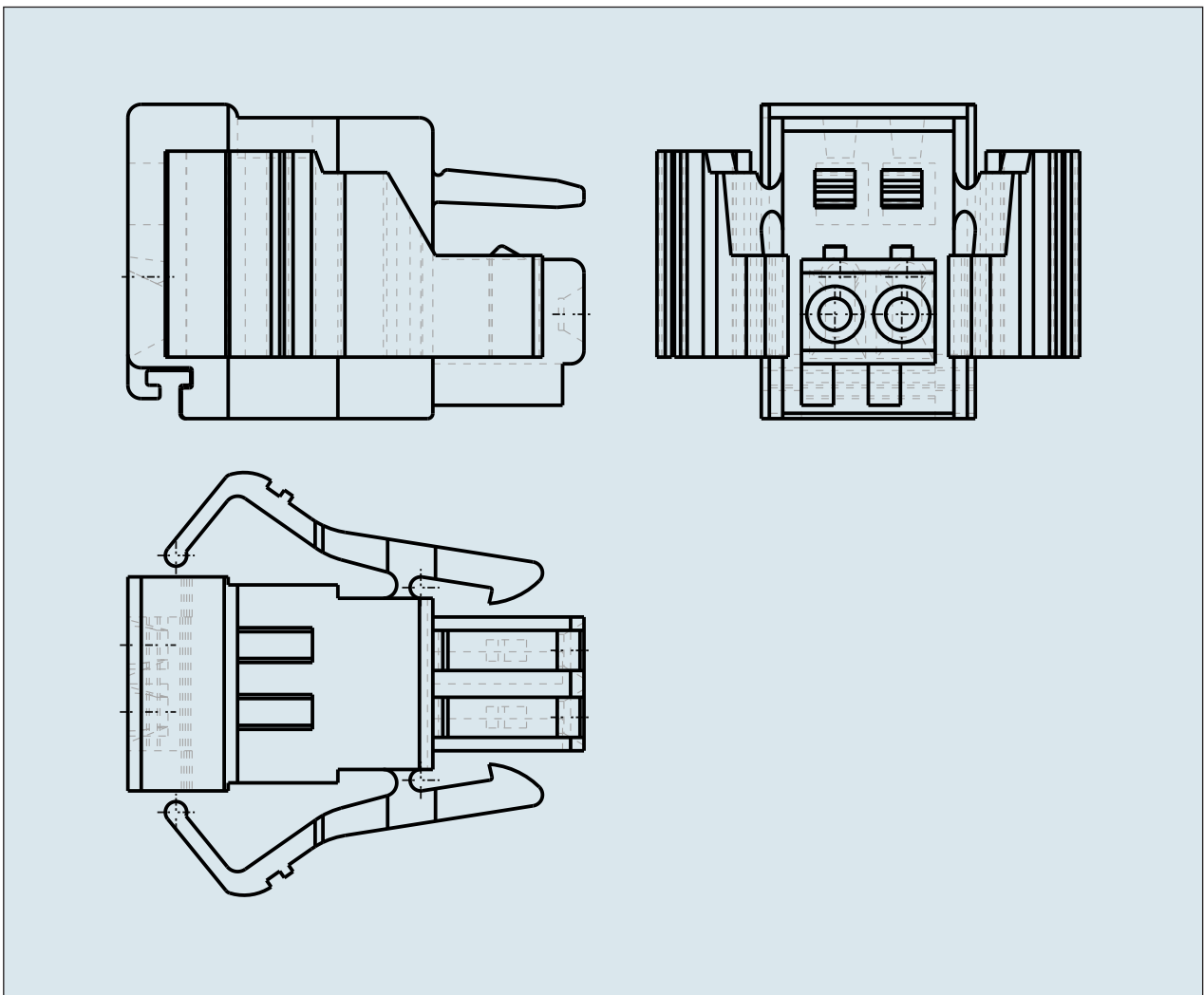


**FEMALE PLUG WITH LOCKING  
LEVER PIN SPACING 3.5 MM / 0.138 IN  
100% PROTECTED AGAINST  
MISMATING**

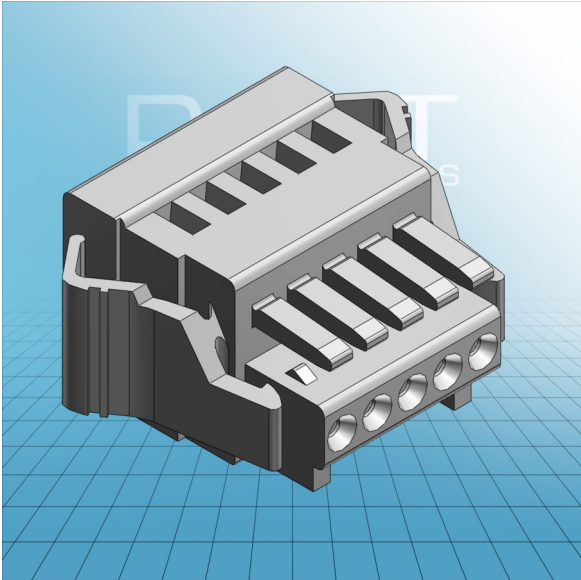

**FEMALE PLUG WITH LOCKING  
LEVER PIN SPACING 3.5 MM / 0.138 IN  
100% PROTECTED AGAINST  
MISMATING**

733-102/037-000 TO 733-112/037-000

ITEM-NO. (ITEM-NO.)	733-105/037-000
Cross section1 (Cross section / mm <sup>2</sup> )	0.08 - 0.5
Cross section2 (Cross section / AWG)	28 - 20
Strip length (Strip length / mm)	5 - 6
Measured voltage (Measured voltage / V)	160
Measured shock voltage (Measured shock voltage / kV)	2.5
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	6
RM (PIN SPACING / mm)	2.5
P (NO. OF POLES)	5
Height (Height / mm)	11.8
Width (Width / mm)	24
Depth (Depth / mm)	17.1
No. of connection Points (No. of connection Points)	5
No. of potentials (No. of potentials)	5
COLOR (COLOR)	lichtgrau
Comment (Comment)	L = (No. of poles x Pin Spacing)