

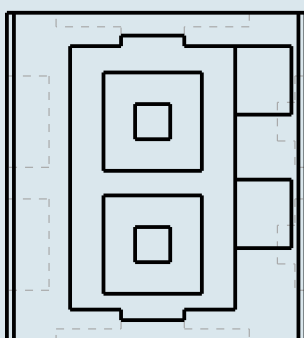
 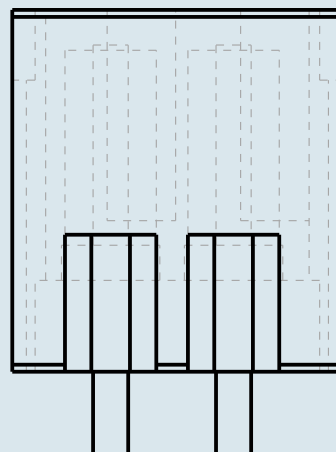
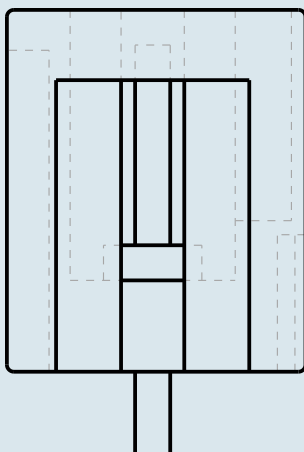




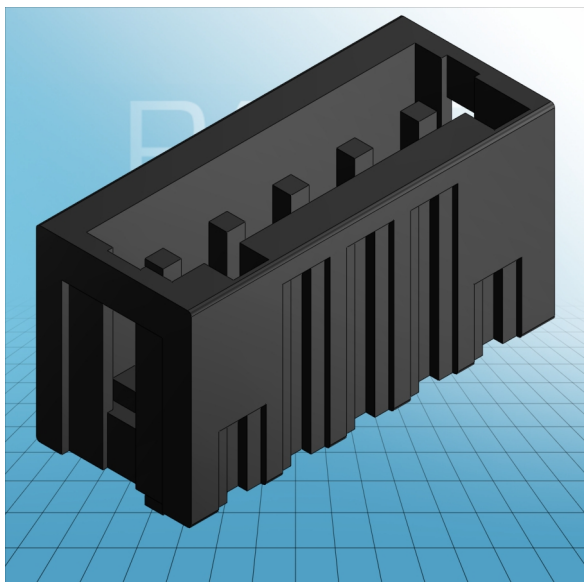

**HEADER STRAIGHT SOLDER PIN, 1X1
MM / 0.039X 0.039 IN PIN SPACING 3.5
MM / 0.138 IN 100% PROTECTED
AGAINST MISMATING
734-132/105-604 TO 734-144/105-604**

PDF DATASHEET

© 1992 - 2011 CADENAS GmbH

ITEM-NO. (ITEM-NO.)	734-135/105-604
Measured voltage (Measured voltage / V)	160
Measured shock voltage (Measured shock voltage / kV)	2.5
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	10
RM (PIN SPACING / mm)	3.5
P (NO. OF POLES)	5
Height (Height / mm)	10.3
Width (Width / mm)	19.9
Depth (Depth / mm)	8.5
COLOR (COLOR)	schwarz
Comment (Comment)	$L = (\text{No. of poles} - 1) \times \text{Pin Spacing} + 5,9 \text{ mm}$
Dimensions (Dimensions)	1,4 +0,1 mm