
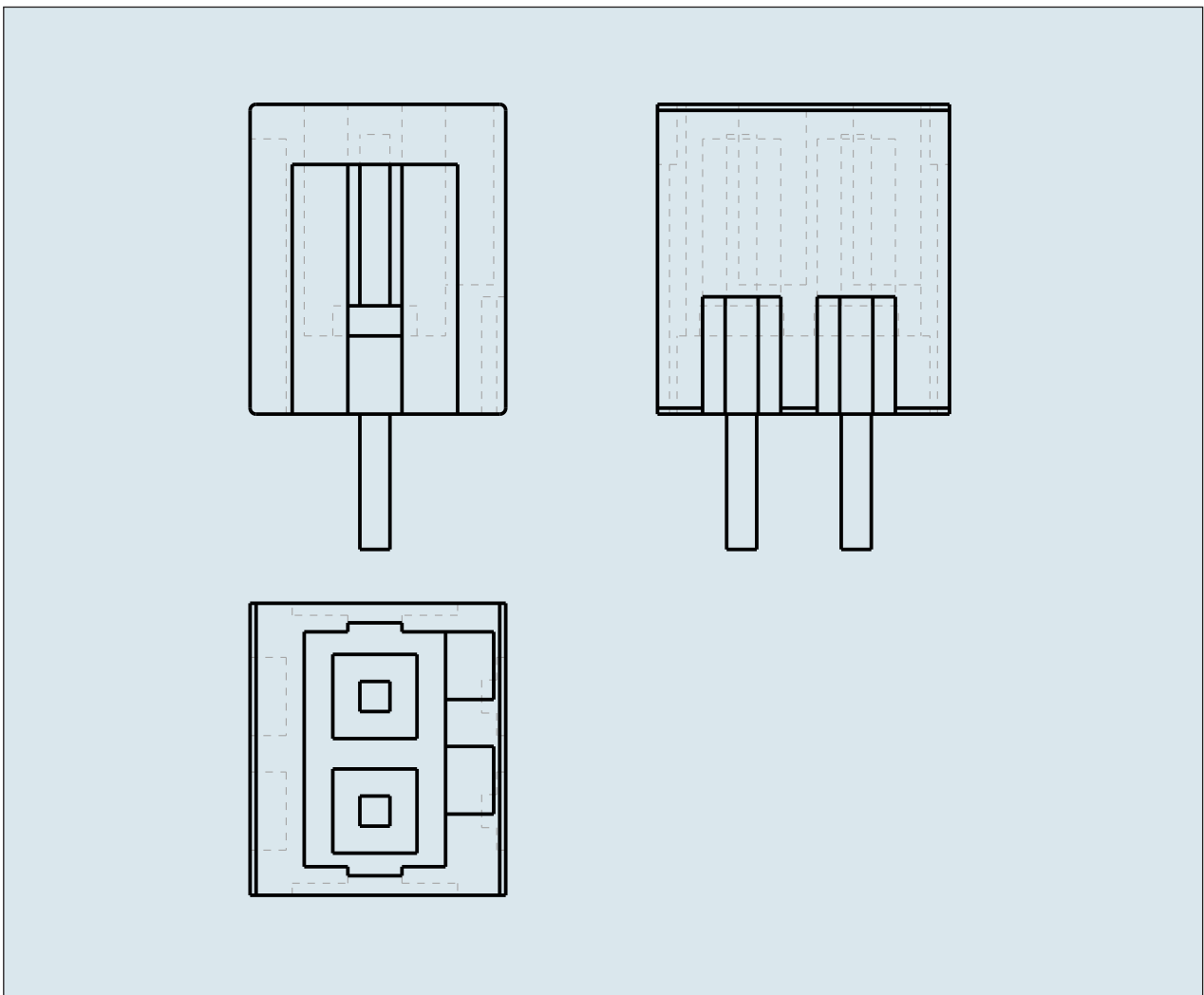


**HEADER STRAIGHT SOLDER PIN, 1X1
MM / 0.039X 0.039 IN PIN SPACING 3.
81 MM / 0.15 IN 100% PROTECTED
AGAINST MISMATING**

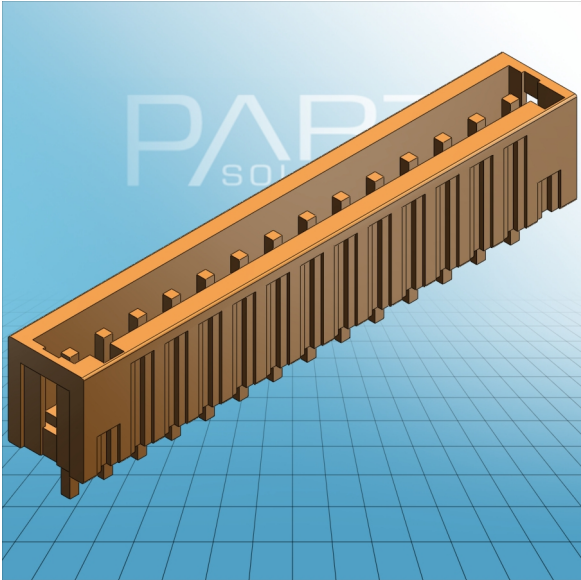

**HEADER STRAIGHT SOLDER PIN, 1X1
MM / 0.039X 0.039 IN PIN SPACING 3.
81 MM / 0.15 IN 100% PROTECTED
AGAINST MISMATING
734-232 TO 734-250**

ITEM-NO. (ITEM-NO.)	734-244
Measured voltage (Measured voltage / V)	160
Measured shock voltage (Measured shock voltage / kV)	2.5
Pollution degree (Pollution degree)	2
Current intensity (Current intensity / A)	10
RM (PIN SPACING / mm)	3.81
P (NO. OF POLES)	14
Height (Height / mm)	10.3
Width (Width / mm)	55.43
Depth (Depth / mm)	8.5
COLOR (COLOR)	orange
WEIGHT (WEIGHT / g)	3.594
Comment (Comment)	L = (No. of poles - 1) x Pin Spacing + 5,9 mm
Dimensions (Dimensions)	1,4 +0,1 mm