





Data sheet | Item number: 756-5101/030-015

Sensor/actuator cable; fitted on one end (with free end); 3-pole; M8 socket, straight; one free cable end; 1.5 m

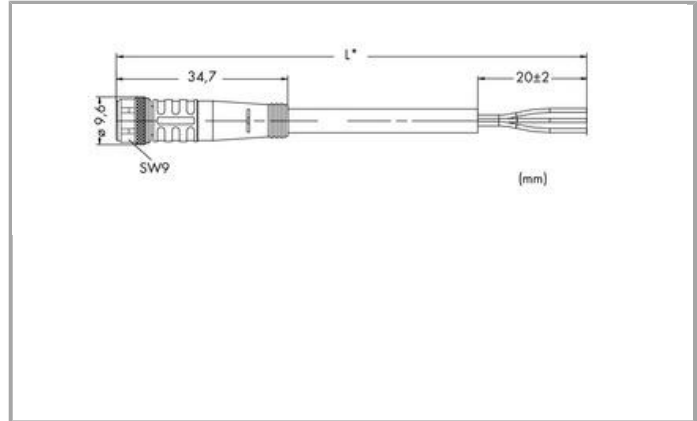

www.wago.com/756-5101/030-015

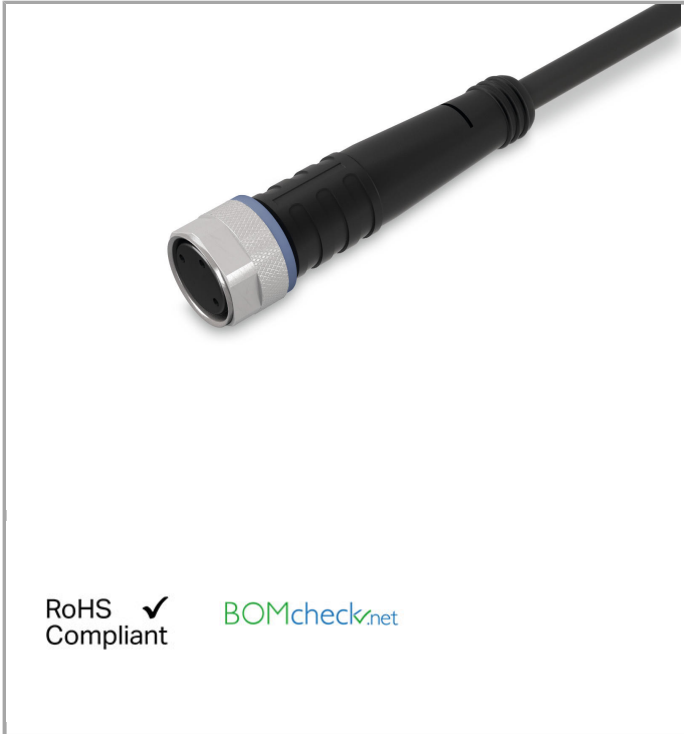

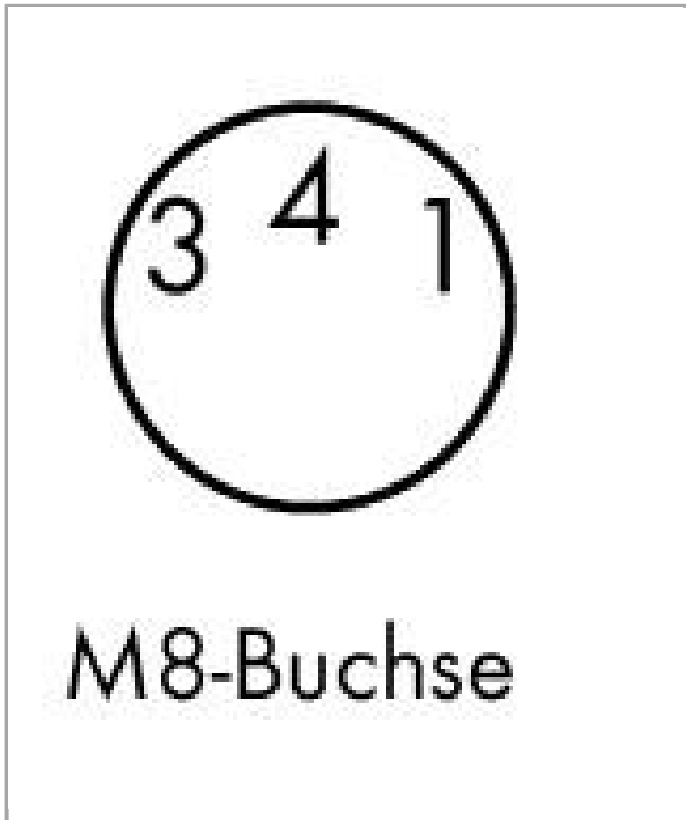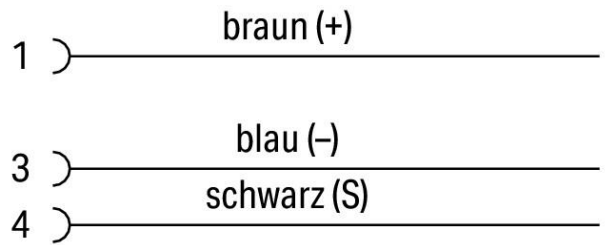Pin 1 ... 4: 0,34 mm²

Item description

Short description:

- PUR, halogen-free
- Suitable for drag chains
- Good resistance to microbes, hydrolysis, oil, chemicals and UV radiation.
- Good chemical resistance.
- Cable used: UL listed

Data

Technical Data

Connection type	M8 socket - free end
No. of poles	3
Leitungsanschlussrichtung zur Steckrichtung	0°
Cable length	1.5 m
Operating voltage	AC/DC 60 V
Operating current	4 A
Rated surge voltage	1,5 kV



Mechanical data

Bending cycles	2
Schleppkettentauglichkeit	yes
Color of sheathed cable	black
Durchmesser der Mantelleitung	3.9 ... 4.3 mm
Sheath material	Polyurethane (OPUR), halogen-free per DIN VDE 0472 Part 815, flame resistant per IEC 332-2, self-extinguishing
Halogen-free	Yes
Housing material	Polyurethan (PUR)
Contact material	CuSn
Contact plating	CuNi/Au
Tightening torque	0.6 Nm
Weight	49 g

Environmental Requirements

Umgebungstemperatur (Betrieb) bewegt	-25 ... +90 °C
Umgebungstemperatur (Betrieb) ruhend	-50 ... +90 °C
Degree of protection	IP67
Degree of pollution (5)	3 acc. to VDE 0110

Commercial data

Country of origin	CZ
GTIN	4044918973298
Customs Tariff No.	85444290900

Downloads

Documentation

System Description

IP67 Cables and Pluggable Connectors	Jun 6, 2017	434.4 kB	Download
--------------------------------------	-------------	----------	--------------------------

Subject to changes.