



### Self-laminating labels, laser

#### • Material 1104 (White-Clear)

#### Features and Benefits

Helatag DIN A4 Laser labels have been especially developed to enable printing of industrial grade labels using standard office laser printers.




Laser Printer



Laminating the mark gives long-term print survivability.

Material Data	
Material	<b>Type 1104, Polyester (PET), white clear (WH/CL), self laminating</b>
Operating Temperature	<b>-40 °C to +150 °C</b>
Curing Temperature	<b>from +5 °C</b>
Adhesive	<b>Acrylic</b>
Thickness of Foil (µm)	<b>23</b>
Chem. Material Properties	<b>Excellent resistance to alcohol, gasoline, cleaning solvents, butanol, ethyl and Butylcellosolve solvent, battery acid.</b>

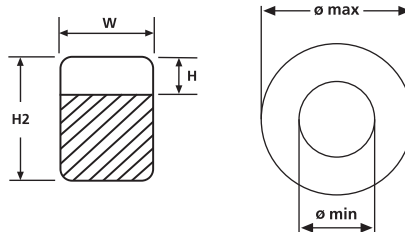

Technical Table

Article-No.	Type	Colour	Bundle Ø min.	Bundle Ø max.	Width (W)	Height (H)	Height (H2)	Labels per Sheet	Pack Cont.
594-11041	<b>TAG26LA4-1104-WHCL</b>	White (WH), Transparent (CL)	1.5	3.00	12.70	9.50	19.05	180	5000
594-21104	<b>TAG130LA4-1104-WHCL</b>	White (WH), Transparent (CL)	2.4	4.80	12.70	9.00	24.00	165	5000
594-11042	<b>TAG49LA4-1104-WHCL</b>	White (WH), Transparent (CL)	2.6	5.30	25.40	8.80	25.40	70	2500
594-31104	<b>TAG131LA4-1104-WHCL</b>	White (WH), Transparent (CL)	3.8	7.60	12.70	12.70	36.50	105	2500
594-41104	<b>TAG132LA4-1104-WHCL</b>	White (WH), Transparent (CL)	3.8	7.60	20.32	12.70	36.50	63	2500
594-01104	<b>TAG02LA4-1104-WHCL</b>	White (WH), Transparent (CL)	3.8	7.60	25.40	12.70	36.50	49	2450
594-51104	<b>TAG133LA4-1104-WHCL</b>	White (WH), Transparent (CL)	5.1	10.10	19.05	12.70	44.50	60	2500
594-61104	<b>TAG134LA4-1104-WHCL</b>	White (WH), Transparent (CL)	5.1	10.10	25.40	12.70	44.50	42	1000
594-11104	<b>TAG09LA4-1104-WHCL</b>	White (WH), Transparent (CL)	5.8	11.60	25.40	19.05	55.50	35	1000
594-71104	<b>TAG135LA4-1104-CLWH</b>	White (WH), Transparent (CL)	6.7	13.50	48.50	12.70	55.00	20	500
594-91104	<b>TAG137LA4-1104-CLWH</b>	White (WH), Transparent (CL)	7.1	14.30	31.75	22.86	67.70	24	1000
594-81104	<b>TAG136LA4-1104-CLWH</b>	White (WH), Transparent (CL)	7.7	15.50	25.40	19.05	67.70	28	1000
594-11040	<b>TAG145LA4-1104-CLWH</b>	White (WH), Transparent (CL)	11.1	22.30	25.40	25.40	95.30	21	1000

All dimensions in mm. Subject to technical changes.