



Cotton Cloth Labels, Manual Marking

• **Material 270 (YE)**

The bright yellow cotton labels are supplied with or without a black border in handy pocket sized booklets. For fast on-site identification of component parts, switching devices and other operating equipment.

The labels are resistant to oils, water and dust and can be removed without leaving a sticky residue. Labels can even be applied to uneven surfaces and are available in different sizes from 15 x 6mm to 38 x 11mm.

The booklet covers act as an effective barrier to dust and dirt so your labels remain clean before use.

An applicator tool is supplied with every HELASIGN booklet for clean application of the labels (e.g. with dirty hands).

For professional hand inscriptions we recommend the T82 marker pen which has fast-drying and UV-resistant ink.



Always on hand: Labels in a convenient, pocket sized and lightweight booklet.




Manual Marking

Material Data	
Material	Type 270, Cotton cloth, yellow (YE)
Operating Temperature	-40 °C to +121 °C
Curing Temperature	From +4 °C
Adhesive	Synthetic rubber
Chem. Material Properties	resistant to oils and water, removable without residue



Technical Table

Article-No.	Type	Colour	Width (W)	Height (H)	Quantity per/book
Fabric labels without border					
598-12027	TAG120B-270-YE	Yellow (YE)	15.00	6.00	1050
598-12227	TAG122B-270-YE	Yellow (YE)	15.00	9.00	700
598-12427	TAG124B-270-YE	Yellow (YE)	19.00	11.00	440
598-12127	TAG121B-270-YE	Yellow (YE)	20.00	8.00	600
Fabric labels with border					
598-92227	TAG122FB-270-YE	Yellow (YE)	15.00	9.00	700
598-92427	TAG124FB-270-YE	Yellow (YE)	19.00	11.00	440
598-92127	TAG121FB-270-YE	Yellow (YE)	20.00	8.00	600
598-92527	TAG125FB-270-YE	Yellow (YE)	38.00	11.00	220
Marker pens T82					
500-50820	T82S-BK	Black (BK)	-	-	
500-50822	T82R-RD	Red (RD)	-	-	

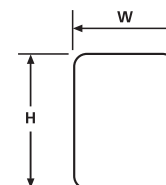

All dimensions in mm. Subject to technical changes.