

Data sheet | Item number: 756-5404/060-010

Sensor/actuator cable; fitted on both ends; 5-pole; M12 socket, angled; M12 plug, angled; 1 m






www.wago.com/756-5404/060-010



RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

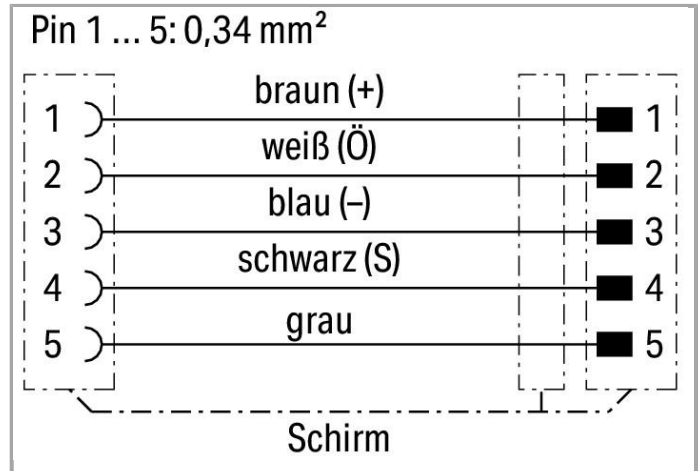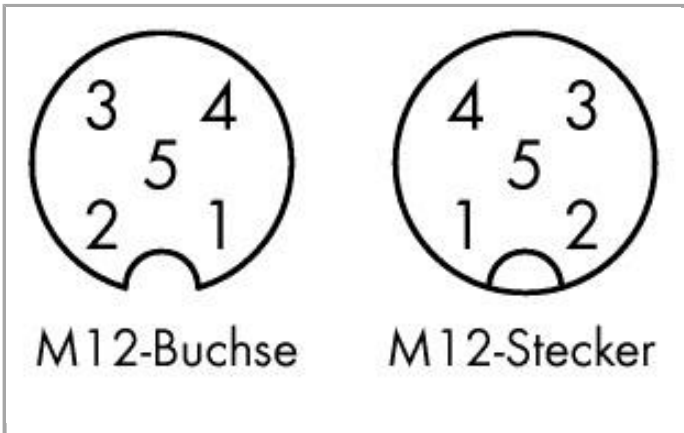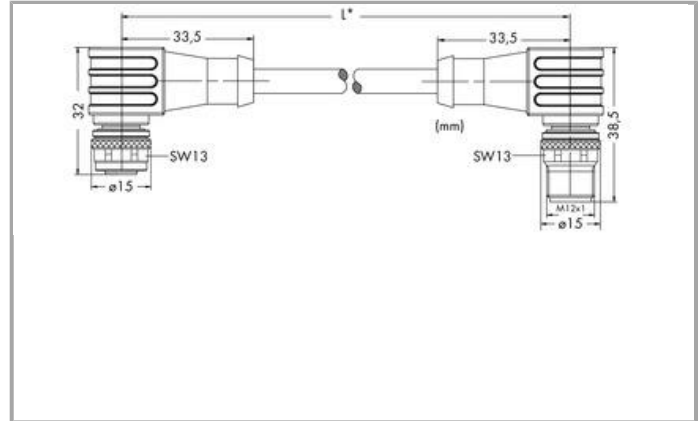

Item description

Short description:

- PUR, halogen-free
- Suitable for drag chains
- Good resistance to microbes, hydrolysis, oil, chemicals and UV radiation.
- Good chemical resistance.
- Cable used: UL listed



Data

Technical Data

Connection type	M12 socket - M12 plug
No. of poles	5
Anschlusspunkt geschirmt	yes
Leitungsanschlussrichtung zur Steckrichtung	90°
Leitungsanschlussrichtung zur Steckrichtung (2)	90°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded
Steckgesichtskodierung Leitung/Adapter 2 1	A coded
Cable length	1 m
Operating voltage	AC/DC 250 V
Operating current	4 A
Rated surge voltage	1,5 kV

Mechanical data

Bending cycles	2
Schleppkettentauglichkeit	yes
Color of sheathed cable	black
Durchmesser der Mantelleitung	6.3 ... 6.7 mm
Sheath material	Polyurethane (OPUR), halogen-free per DIN VDE 0472 Part 815, flame resistant per IEC 332-2, self-extinguishing
Halogen-free	Yes
Housing material	Polyurethan (PUR)
Contact material	CuSn
Contact plating	CuNi/Au
Tightening torque	1 Nm
Weight	10.5 g

Environmental Requirements

Umgebungstemperatur (Betrieb) bewegt	-25 ... +90 °C
Umgebungstemperatur (Betrieb) ruhend	-50 ... +90 °C
Degree of protection	IP67
Degree of pollution (5)	3 acc. to VDE 0110

Commercial data

Country of origin	HU
GTIN	4045454724580
Customs Tariff No.	85444290900



Downloads

Documentation

System Description

IP67 Cables and Pluggable Connectors

Jun 6, 2017

Download

434.4 kB

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.