



Data sheet | Item number: 756-9102/030-000

Connectors for sensor/actuator cable; 3-pole; M8 plug, straight

[www.wago.com/756-9102/030-000](http://www.wago.com/756-9102/030-000)

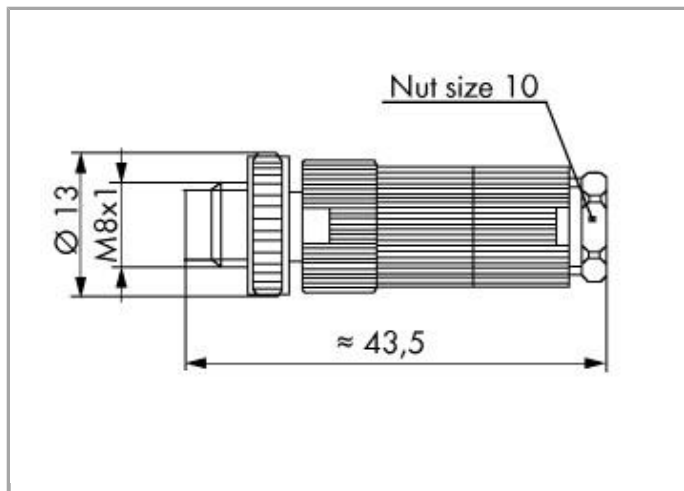

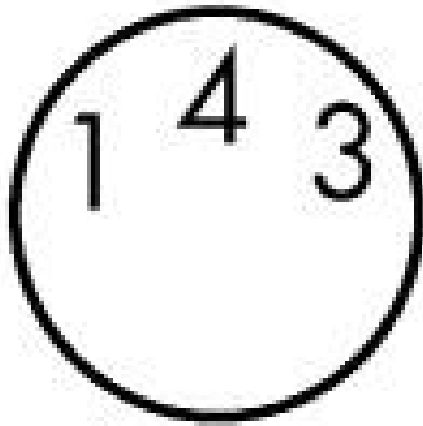

M8-Stecker

Anschließbare Leitung  
 $\varnothing 4 \dots 5 \text{ mm} / 0,14 \dots 0,34 \text{ mm}^2$

#### Data

##### Technical Data

Connection type	M8 plug
No. of poles	3
Leistungsanschlussrichtung zur Steckrichtung	0°

##### Connection data

Connection type (1)	Eindringtechnik
Solid conductor	0.14 ... 0.34 mm <sup>2</sup> / ...

##### Mechanical data

Connectable sheathed cable diameter	4 ... 5 mm
Weight	13.9 g

##### Environmental Requirements

Degree of protection	IP67
Fire load	0.115 MJ



## Commercial data

Country of origin	DE
GTIN	4044918977333
Customs Tariff No.	85366990990

## Downloads

### Documentation

#### System Description

IP67 Cables and Pluggable Connectors	Jun 6, 2017	Download
		434.4 kB

Subject to changes.