



Data sheet | Item number: 756-9105/030-000

Connectors for sensor/actuator cable; 3-pole; M8 plug, angled

www.wago.com/756-9105/030-000

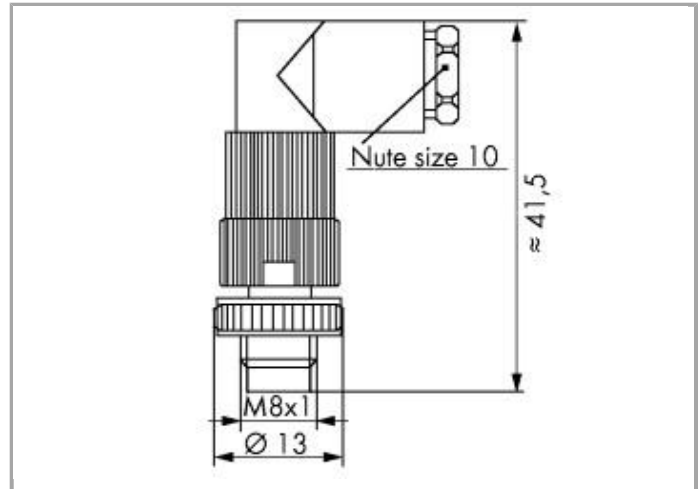

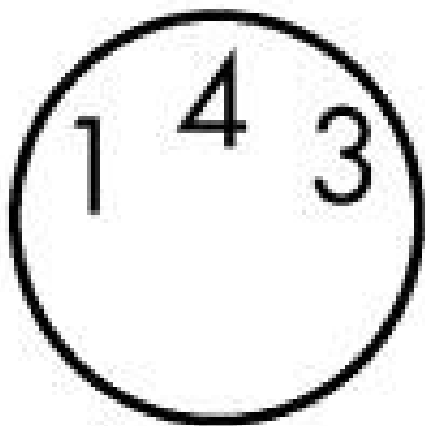

M8-Stecker

Anschließbare Leitung
 $\varnothing 4 \dots 5 \text{ mm} / 0,14 \dots 0,34 \text{ mm}^2$

Data

Technical Data

Connection type	M8 plug
No. of poles	3
Leitungsanschlussrichtung zur Steckrichtung	90°

Connection data

Connection type (1)	Eindringtechnik
Solid conductor	0.14 ... 0.34 mm ² / ...

Mechanical data

Connectable sheathed cable diameter	4 ... 5 mm
Weight	14.5 g

Environmental Requirements

Degree of protection	IP67
Fire load	0.143 MJ



Commercial data

Country of origin	DE
GTIN	4044918977357
Customs Tariff No.	85366990990

Downloads

Documentation

System Description

IP67 Cables and Pluggable Connectors	Jun 6, 2017	Download
		434.4 kB

Subject to changes.