


Data sheet | Item number: 756-9201/040-000


Connectors for sensor/actuator cable; 4-pole; M12 plug, straight

www.wago.com/756-9201/040-000

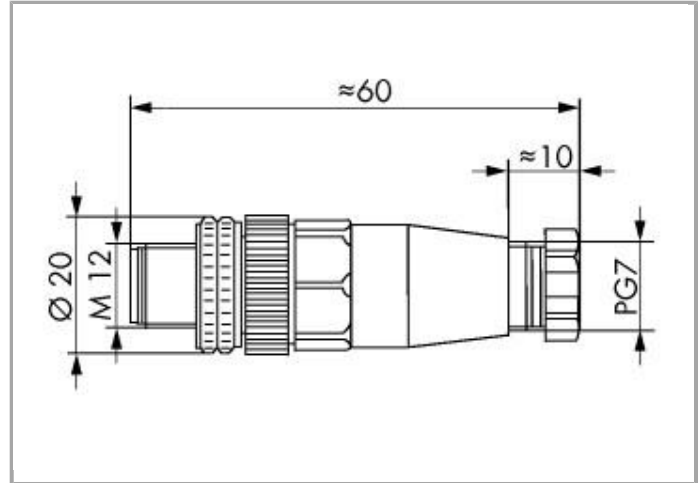

RoHS
 Compliant

BOMcheck.net

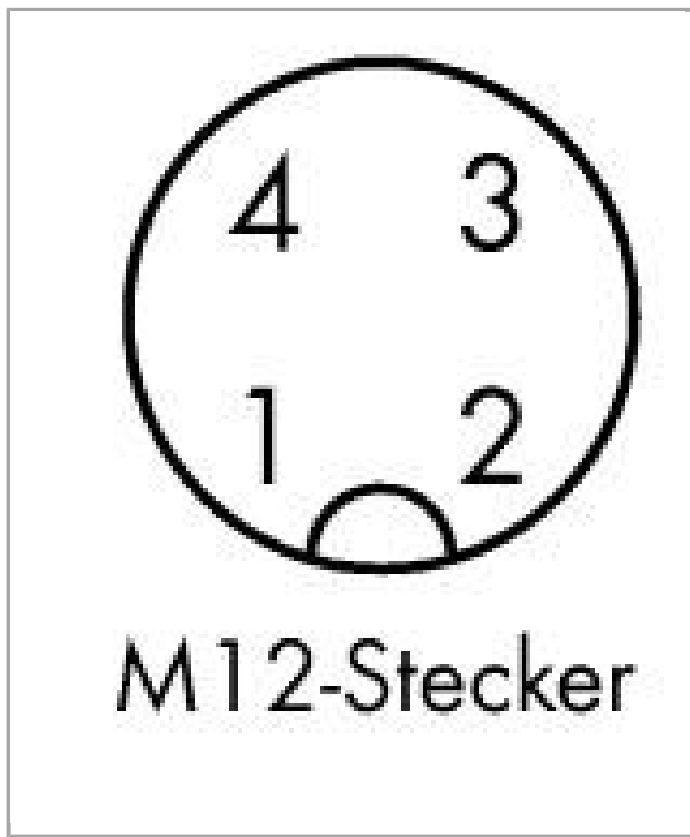

Anschließbare Leitung
Ø 4 ... 6 mm / 0,25 - 0,75 mm²

Data

Technical Data

Connection type	M12 plug
No. of poles	4
Leistungsanschlussrichtung zur Steckrichtung	0°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded

Connection data

Connection type (1)	Schraubtechnik
Solid conductor	0.25 ... 0.75 mm ² / ...

Mechanical data

Connectable sheathed cable diameter	4 ... 6 mm
Weight	24 g

Environmental Requirements

Degree of protection	IP67
----------------------	------



Commercial data

Country of origin	HU
GTIN	4044918977401
Customs Tariff No.	85366990990

Downloads

Documentation

Bid Text

756-9201/040-000	Apr 5, 2012	DOC	Download
AS Interface		20.5 kB	

System Description

IP67 Cables and Pluggable Connectors	Jun 6, 2017		Download
		434.4 kB	

Subject to changes.