
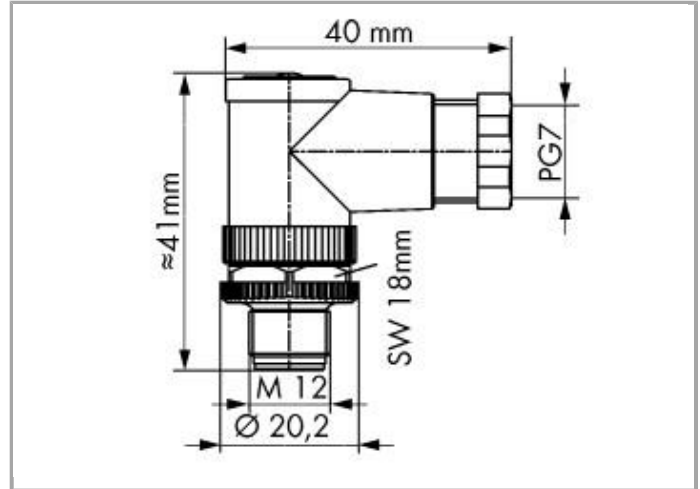


Data sheet | Item number: 756-9205/050-000


Connectors for sensor/actuator cable; M12 plug, angled; 5-pole

www.wago.com/756-9205/050-000

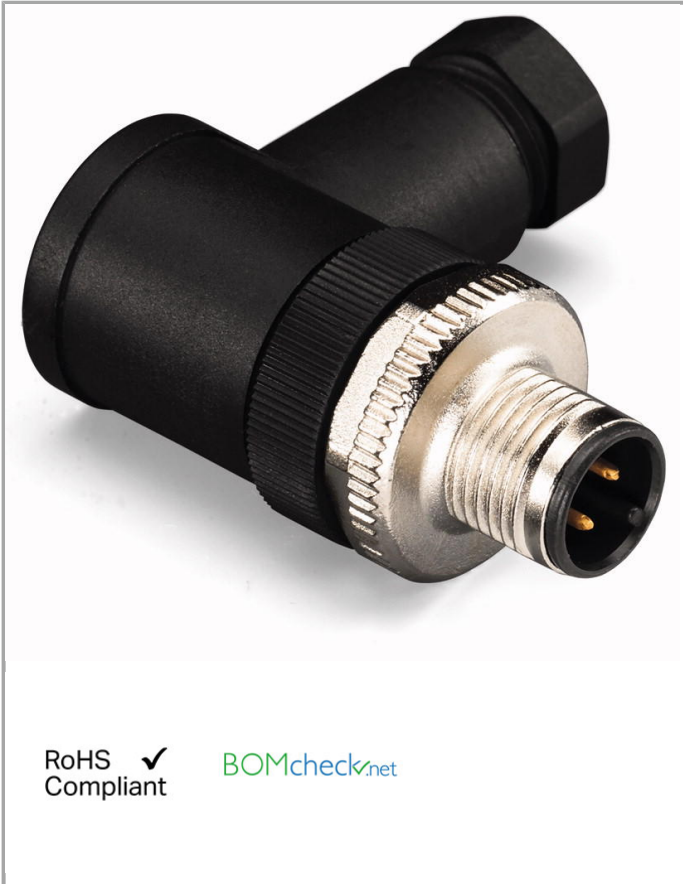

RoHS Compliant

[BOMcheck.net](https://www.bomcheck.net)

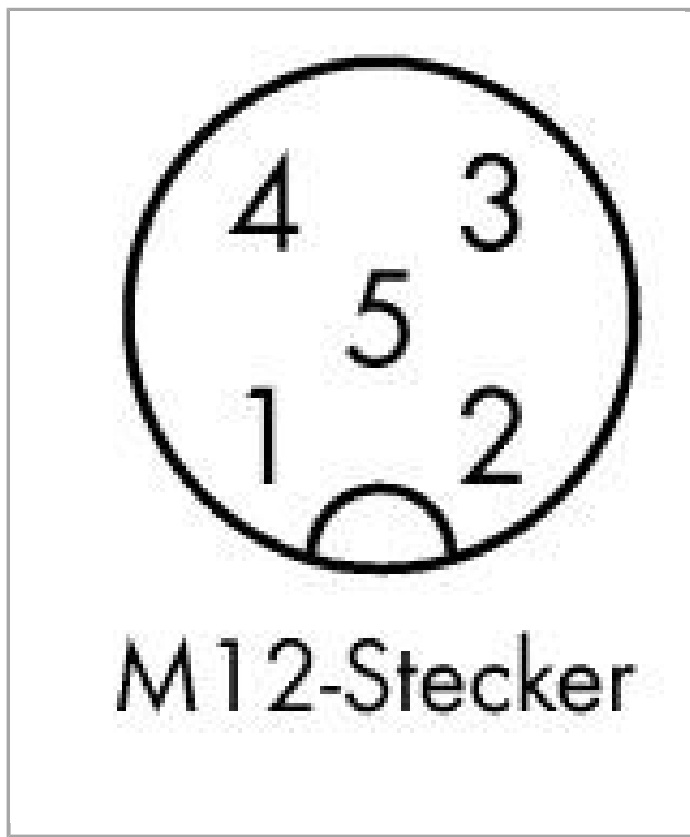

Anschließbare Leitung
Ø 4 ... 6 mm / 0,14 - 0,50 mm²

Data

Technical Data

Connection type	M12 plug
No. of poles	5
Leitungsanschlussrichtung zur Steckrichtung	90°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded

Connection data

Connection type (1)	Federtechnik
Solid conductor	0.14 ... 0.5 mm ² / ...

Mechanical data

Connectable sheathed cable diameter	4 ... 6 mm
Weight	25 g

Environmental Requirements

Degree of protection	IP67
----------------------	------



Commercial data

Country of origin	DE
GTIN	4044918977500
Customs Tariff No.	85369010000

Downloads

Documentation

System Description

IP67 Cables and Pluggable Connectors	Jun 6, 2017	Download
		434.4 kB

Subject to changes.