


RoHS  Compliant

[BOMcheck.net](https://www.bomcheck.net)

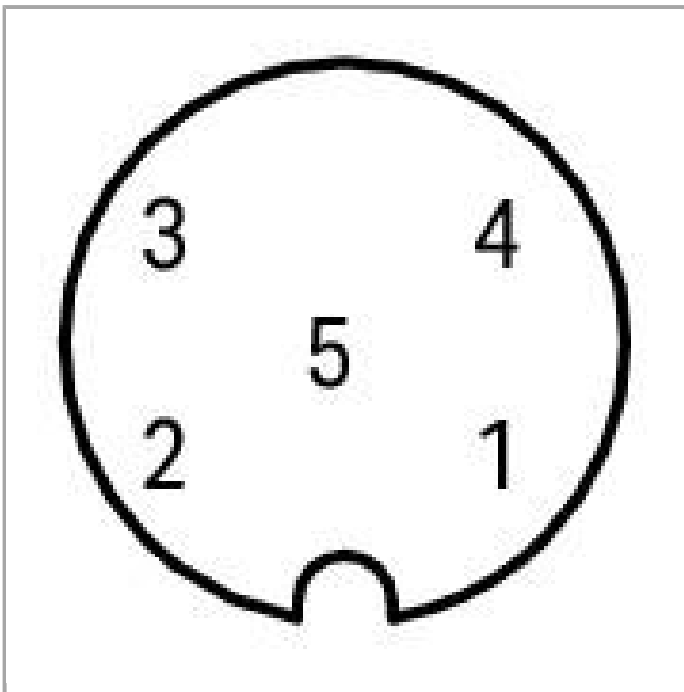

Anschließbare Leitung  
Ø 6 ... 8 mm / 0,14 - 0,5 mm<sup>2</sup>

Data  
Technical Data



Connection type	M12 socket
No. of poles	5
Anschlusspunkt geschirmt	yes
Leitungsanschlussrichtung zur Steckrichtung	90°
Steckgesichtskodierung Leitung/Adapter 1 1	A coded

**Connection data**

Connection type (1)	Federtechnik
Solid conductor	0.14 ... 0.5 mm <sup>2</sup> / ...

**Mechanical data**

Connectable sheathed cable diameter	6 ... 8 mm
Weight	70 g

**Environmental Requirements**

Degree of protection	IP67
----------------------	------

**Commercial data**

Country of origin	DE
GTIN	4045454686406
Customs Tariff No.	85369010000

**Downloads****Documentation****System Description**

IP67 Cables and Pluggable Connectors	Jun 6, 2017	434.4 kB	Download
767 Series, SPEEDWAY accessories, data sheet	May 16, 2018	1.0 MB	Download

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG  
Hansastr. 27  
32423 Minden  
Phone: +49571 887-0 | Fax: +49571 887-169  
Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?  
We are always happy to take your call at +49 (571) 887-44222.