



Data sheet | Item number: 756-9211/040-000

Connectors for sensor/actuator cable; M12 socket, straight; 4-pole

[www.wago.com/756-9211/040-000](http://www.wago.com/756-9211/040-000)

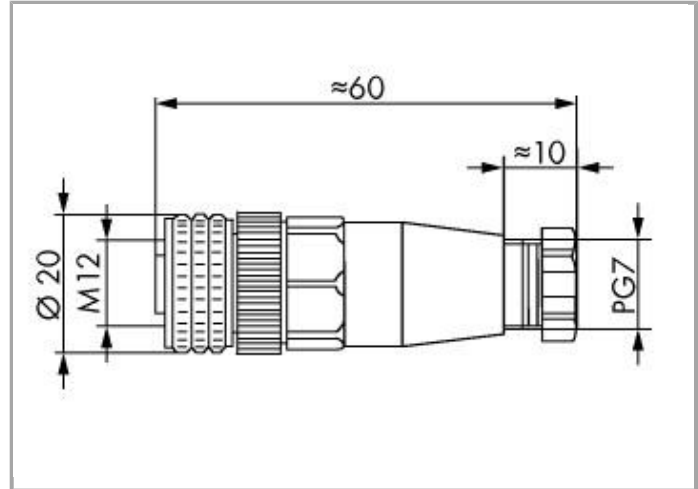

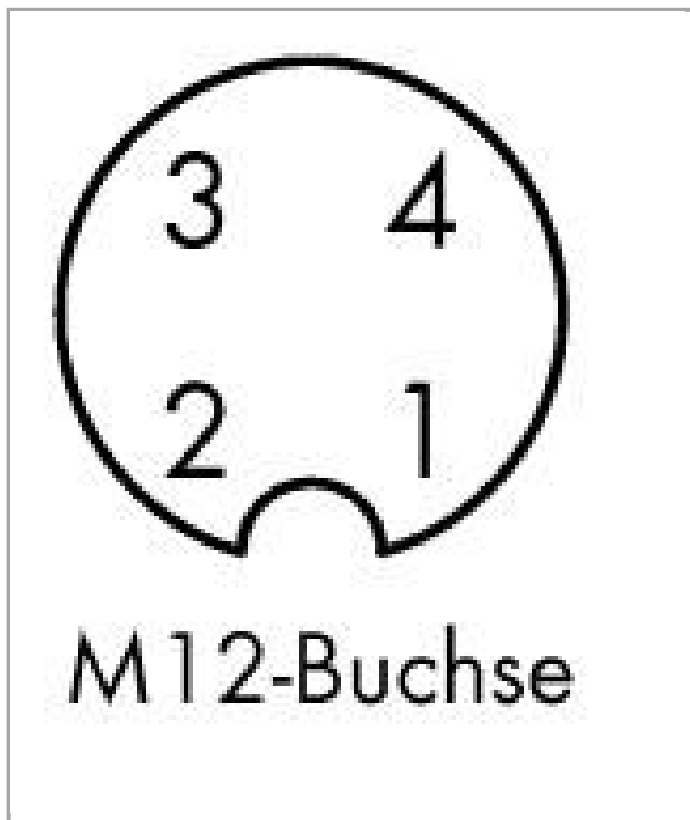

Anschließbare Leitung  
Ø 4 ... 6 mm / 0,25 - 0,75 mm<sup>2</sup>

#### Data

##### Technical Data

Connection type	M12 socket
No. of poles	4
Leitungsanschlussrichtung zur Steckrichtung	0°
Steckgesichtkodierung Leitung/Adapter 1 1	A coded

##### Connection data

Connection type (1)	Schraubtechnik
Solid conductor	0.25 ... 0.75 mm <sup>2</sup> / ...

##### Mechanical data

Connectable sheathed cable diameter	4 ... 6 mm
Weight	23.8 g

##### Environmental Requirements

Degree of protection	IP67
----------------------	------



## Commercial data

Country of origin	HU
GTIN	4045454325589
Customs Tariff No.	85366990990

## Downloads

### Documentation

#### System Description

IP67 Cables and Pluggable Connectors	Jun 6, 2017	Download
		434.4 kB

Subject to changes.