

Data sheet | Item number: 756-9501/040-000



M12 plug; D-coded; angled; configurable

www.wago.com/756-9501/040-000



RoHS
Compliant

BOMcheck.net

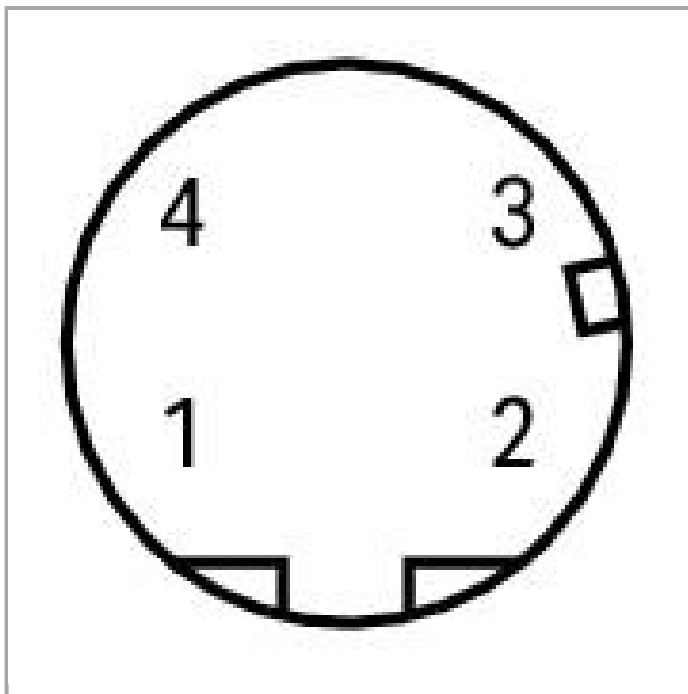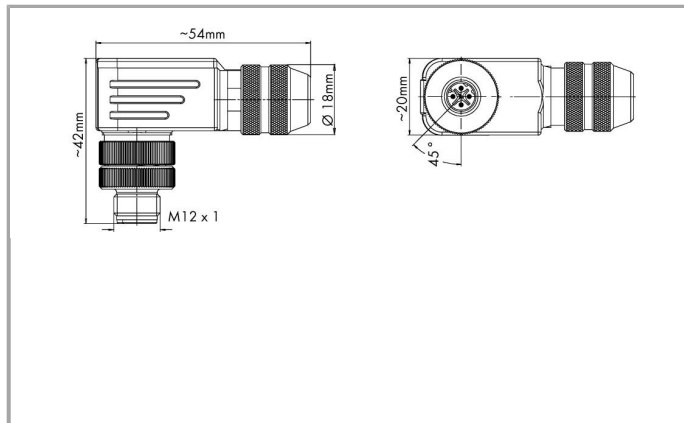

Anschließbare Leitung
Ø 6 ... 8 mm / 0,14 - 0,5 mm²

Data



Technical Data

Connection type	M12 plug
No. of poles	4
Anschlusspunkt geschirmt	yes
Leitungsanschlussrichtung zur Steckrichtung	90°
Steckgesichtskodierung Leitung/Adapter 1 1	D coded

Connection data

Connection type (1)	Federtechnik
Solid conductor	0.14 ... 0.5 mm ² / ...

Mechanical data

Connectable sheathed cable diameter	6 ... 8 mm
Weight	6.5 g

Environmental Requirements

Surrounding air (operating) temperature	-25 ... 85 °C
Degree of protection	IP67

Commercial data

Country of origin	DE
GTIN	4045454686444
Customs Tariff No.	85369010000

Downloads

Documentation

System Description

767 Series, SPEEDWAY accessories, data sheet	May 16, 2018	1.0 MB	Download
--	--------------	--------	--------------------------

Subject to changes.